


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 25mm VIS 0° Coated, BBAR Coated Right Angle Prism

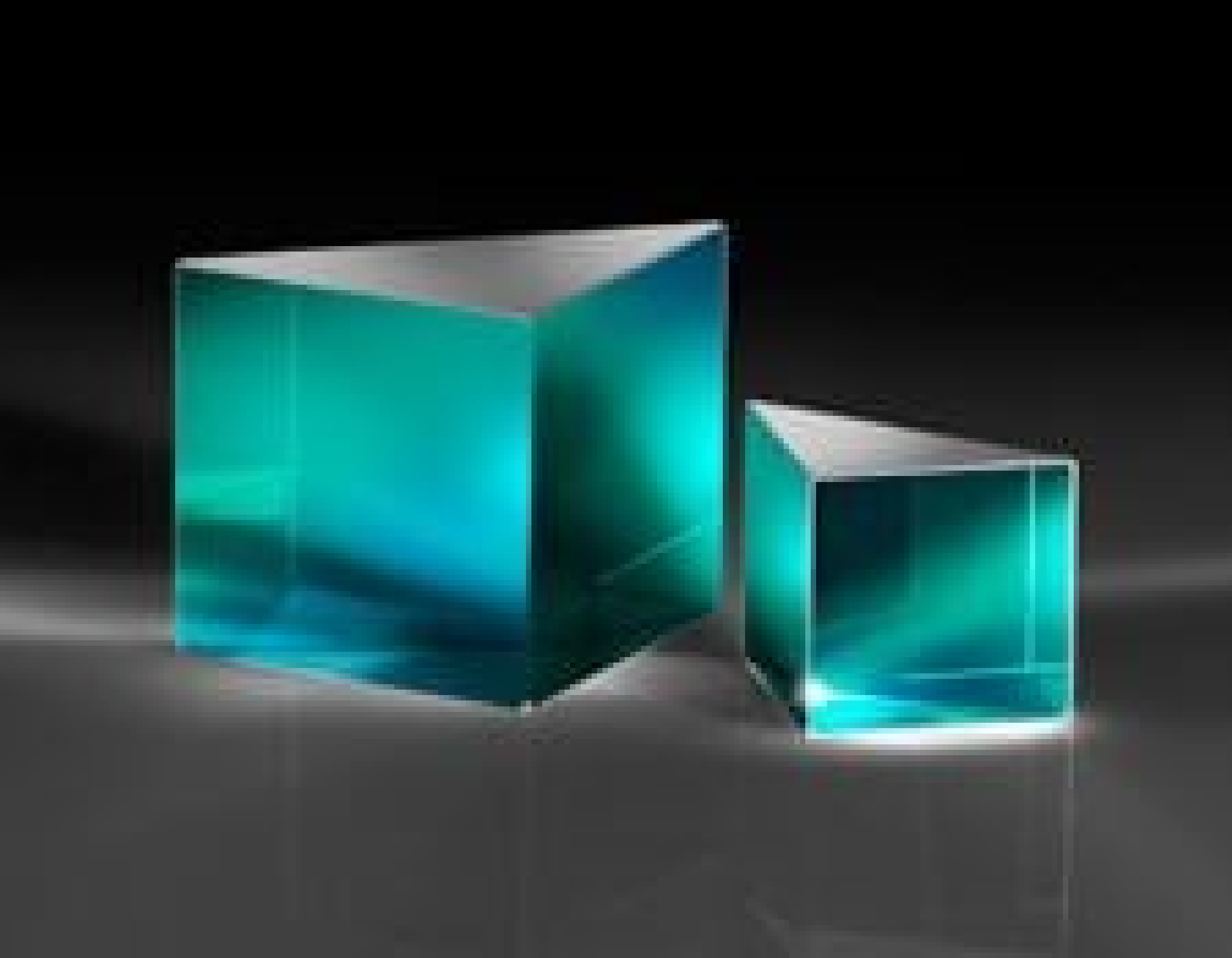

Stock #84-510 3-4 DAYS



1



€129,00

ADD TO CART

Qty 1-5

€129,00

Qty 6+

€103,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle Tolerance (arcsec):
±15

Coating:
VIS 0° (425-675nm)

Substrate: ☐
[N-BK7](#)

Surface Quality: 40-20
Type: Right Angle Prism
Dimensional Tolerance (mm): +0.00/-0.10
Bevel: Protective bevel as needed
Clear Aperture (%): 90
Length of Hypotenuse (mm): 35.40
Length of Legs (mm): 25.00
Image Orientation: Left-Handed
Note: Coating on Entrance/Exit Faces
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 90
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8
Damage Threshold, Reference: ☐ Entrance/Exit Faces: 5 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View