


27mm Diameter Float Glass Window

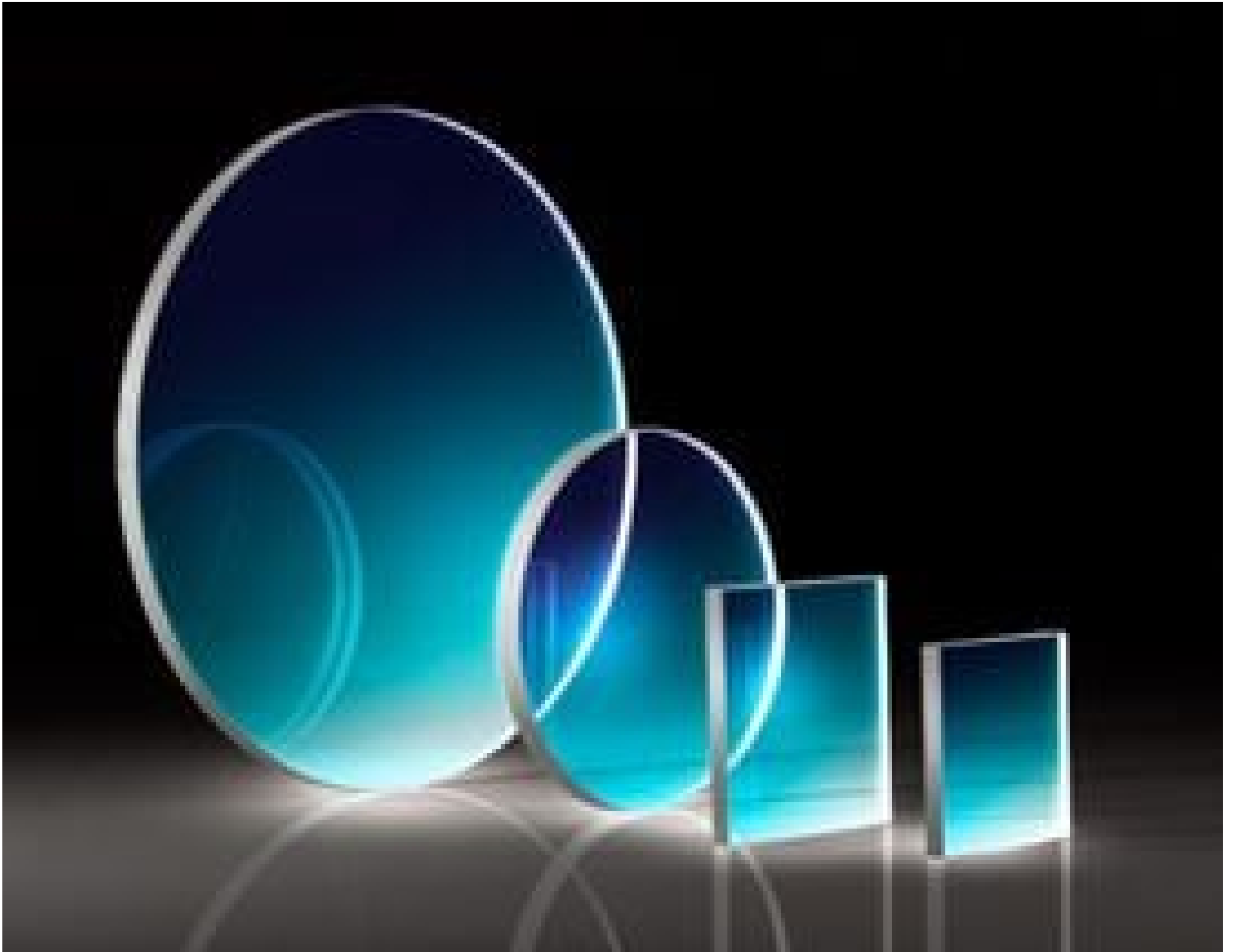

Stock #02-199 **20+ In Stock**

€15^{.97}

ADD TO CART

Volume Pricing	
Qty 1-5	€15,97 each
Qty 6-49	€14,42 each
Qty 50-99	€13,65 each
Need More?	Request Quote

! Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Protective Window **Type:**

Physical & Mechanical Properties

27.00 **Diameter (mm):**

1.50 **Thickness (mm):**

Fine Ground **Edges:**

Optical Properties

Uncoated **Coating:**

Float Glass **Substrate:**

4 - 6λ **Surface Flatness (P-V):**

80-50 **Surface Quality:**

350 - 2000 **Wavelength Range (nm):**

Regulatory Compliance

[Compliant](#) **RoHS 2015:**

[Compliant](#) **Reach 219:**

[View](#) **Certificate of Conformance:**

PRODUCT DETAILS

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

COMPATIBLE MOUNTS