


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

2" X 2", Line Grid Low Reflective Chrome

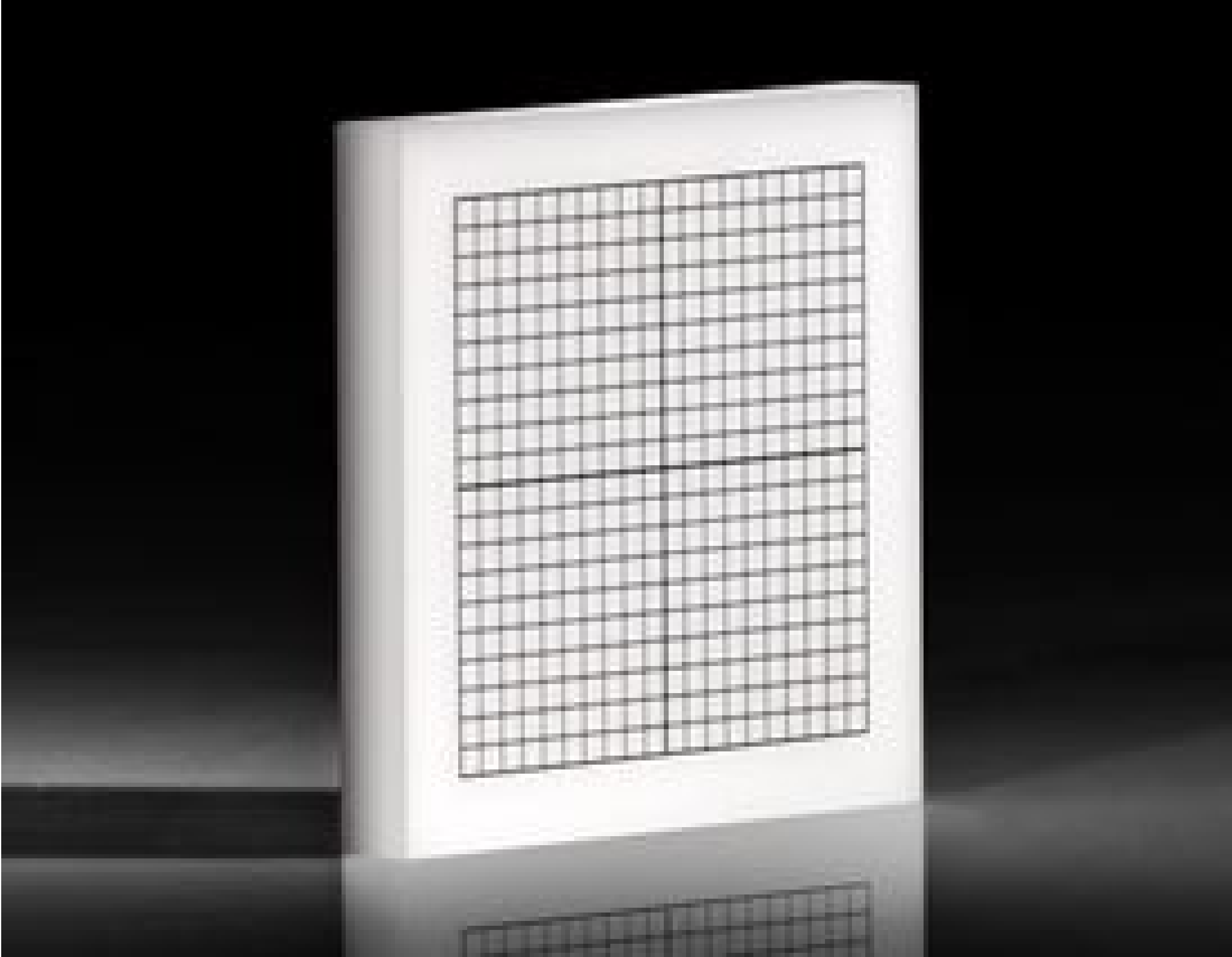

Line Grid Low Reflective Chrome

Stock #62-538 3-4 DAYS



1



€736,00

ADD TO CART

Qty 1-4

€736,00

Qty 5+

€699,30

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate:

White Soda Lime Glass

Length (mm):

50.80

Optical Density OD (Average):

>3.0

Overall Accuracy (mm): ±0.002
Pattern Size (mm): 30.1 x 30.1
Surface Quality: 20-10 over active area, 60-40 outside
Thickness (mm): 2.50
Width (mm): 50.80
Line Thickness (mm): Center Line: 0.1 ±0.002 Inner Line: 0.075 ±0.002
Center to Center Spacing (mm): 1.00 ±0.001
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
