

**TECHSPEC® 30mm, Center Drive, Standard Top, 0.5" Travel, English Micrometer**



Stock #66-387 **2 In Stock**

- 1 + €438.<sup>00</sup>

**ADD TO CART**

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-2        | €438,00 each                  |
| Qty 3+         | €382,00 each                  |
| Need More?     | <a href="#">Request Quote</a> |

Prices shown are exclusive of VAT/local taxes

Product Downloads

**General**

English Type:


**Physical & Mechanical Properties**

Linear (X) Type of Movement:


Crossed Roller Bearing Guide System:




**30mm Standard-Top Stages - Center Drive**

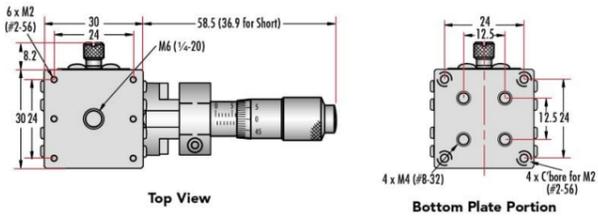


**30mm Standard-Top Stages - Side Drive**

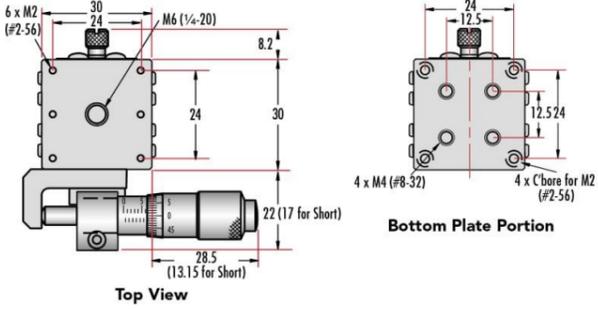


**40mm Standard-Top Stages - Center Drive**

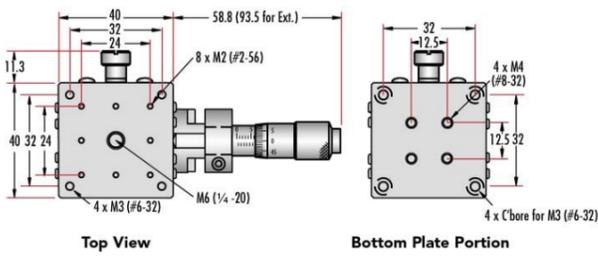


**40mm Standard-Top Stages - Side Drive**

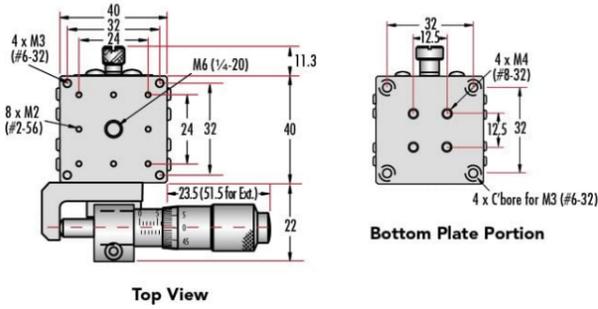


**70mm Standard-Top Stages - Center Drive**

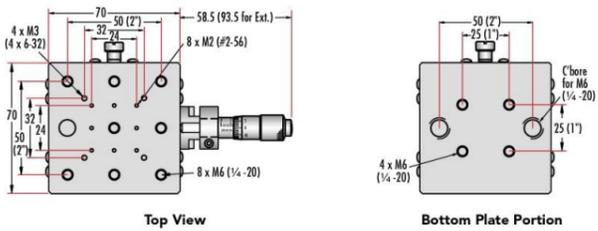

**70mm Standard-Top Stages - Side Drive**

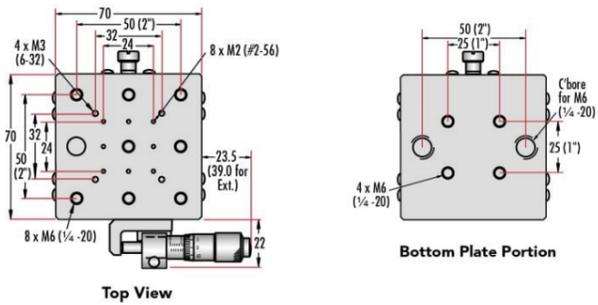

**125mm Standard-Top Stages - Center Drive**

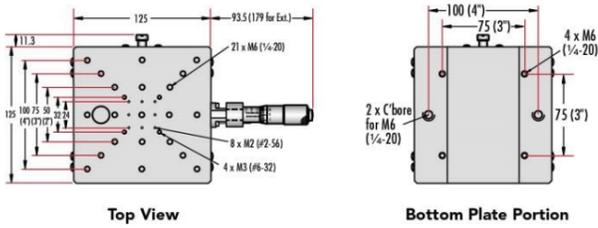

**125mm Standard-Top Stages - Side Drive**

