


# 3.5 OD 12.5mm Dia, Absorptive ND Filter

See More by [Hoya](#)

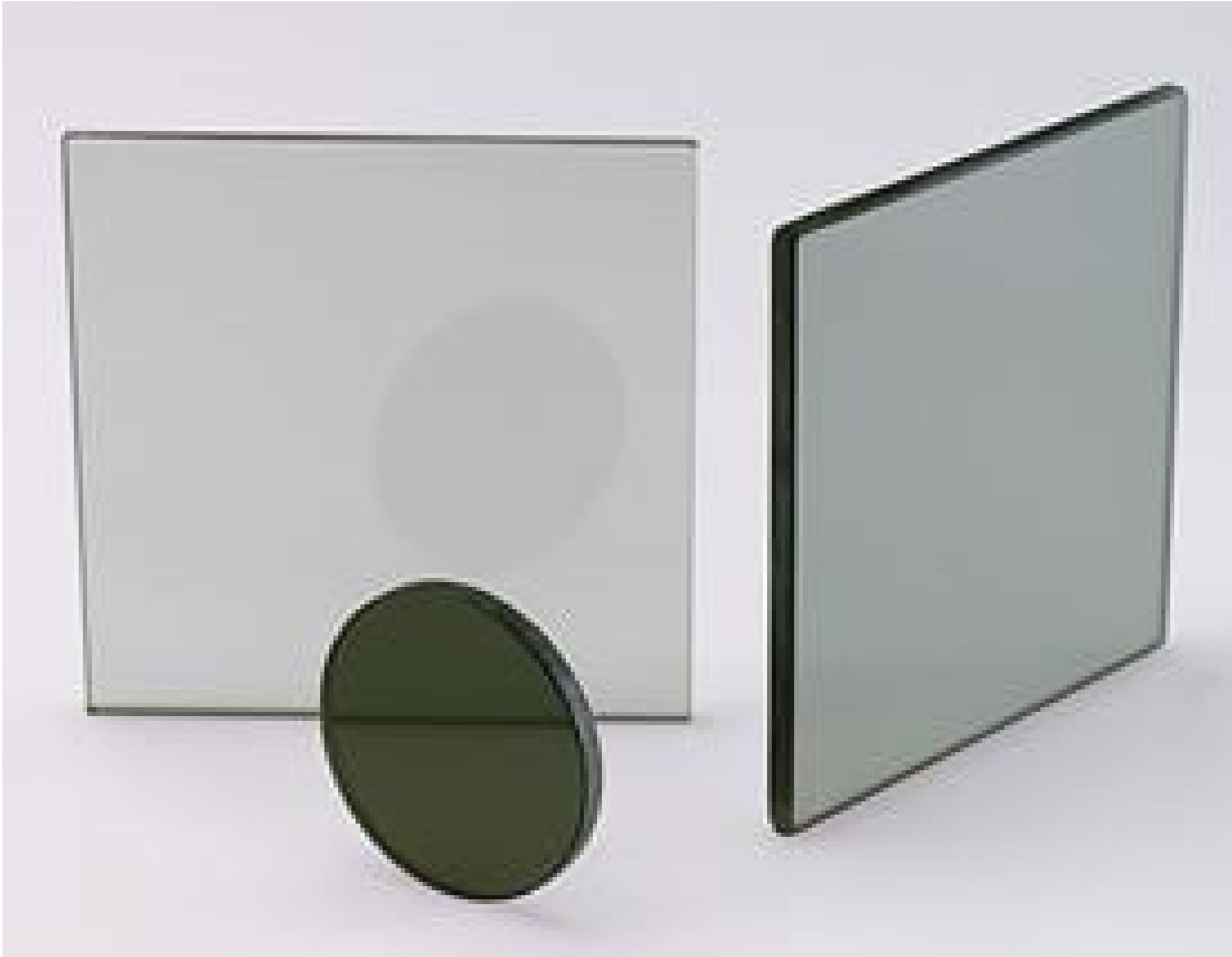

Stock **#36-268** ☐ In Stock

-

1

+

**€31,00**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| €31,00                        |
| Qty 11+                       |
| €28,00                        |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):  
12.50

Optical Density OD (Average):

|                                                               |
|---------------------------------------------------------------|
| 3.5 ±0.2                                                      |
| <b>Glass/Filter Number:</b><br><a href="#">Hoya ND-006</a>    |
| <b>Substrate:</b> <input type="checkbox"/><br>ND Filter Glass |
| <b>Coating:</b><br>Uncoated                                   |
| <b>Index of Refraction n<sub>d</sub>:</b><br>1.531            |
| <b>Surface Quality:</b><br>80-50                              |
| <b>Transformation Temperature (°C):</b><br>542.00             |
| <b>Thickness (mm):</b><br>2.50                                |
| <b>Thickness Tolerance (mm):</b><br>±0.5                      |
| <b>Transmission (%):</b><br>0.03 (average)                    |
| <b>Type:</b><br>Neutral Density Filter                        |
| <b>Blocking Wavelength Range (nm):</b><br>400 - 700           |
| <b>Dimensional Tolerance (mm):</b><br>±0.1                    |
| <b>Parallelism (mm):</b><br><0.02                             |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>REACH 201:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |