

TECHSPEC® 40mm, Center Drive, Standard Top, Metric Extended Micrometer



Stock **#66-410** **12 In Stock**

- 1 + €460.⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	€460,00 each
Qty 3+	€401,60 each
Need More?	Request Quote

! Prices shown are exclusive of VAT/local taxes

Product Downloads

General


Metric Type:

Physical & Mechanical Properties


Linear (X) Type of Movement:

Crossed Roller Bearing Guide System:


30mm Standard-Top Stages - Center Drive

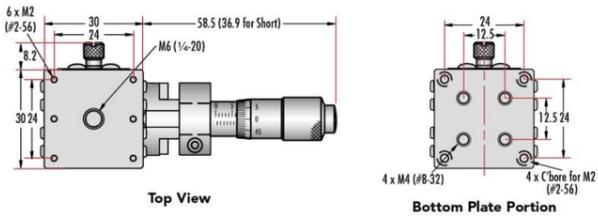


30mm Standard-Top Stages - Side Drive

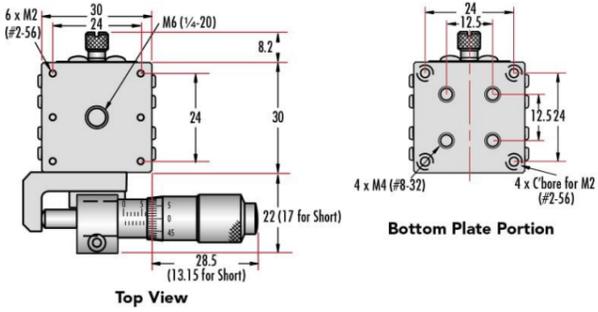


40mm Standard-Top Stages - Center Drive

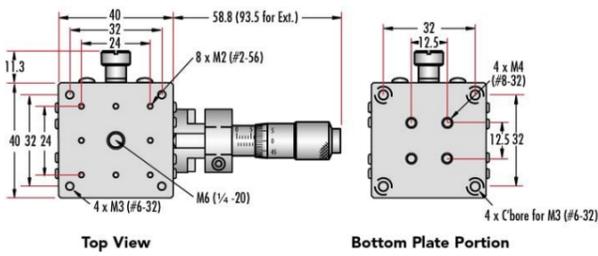


40mm Standard-Top Stages - Side Drive

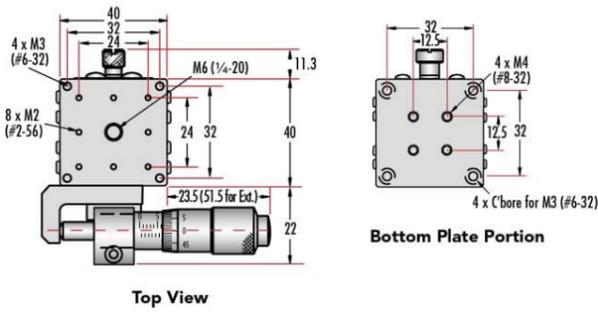


70mm Standard-Top Stages - Center Drive

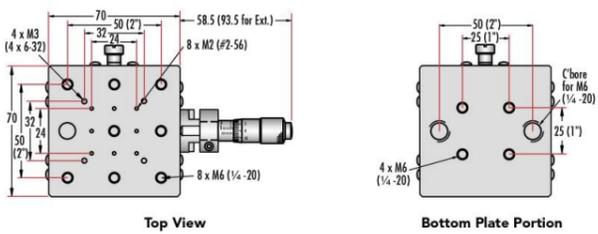

70mm Standard-Top Stages - Side Drive

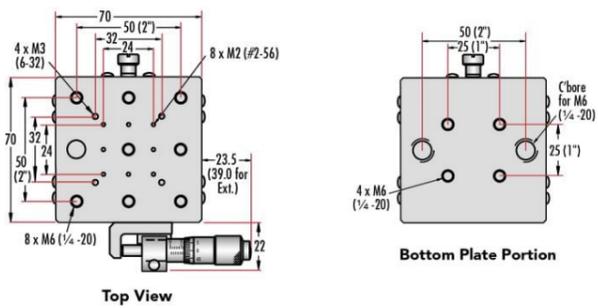

125mm Standard-Top Stages - Center Drive

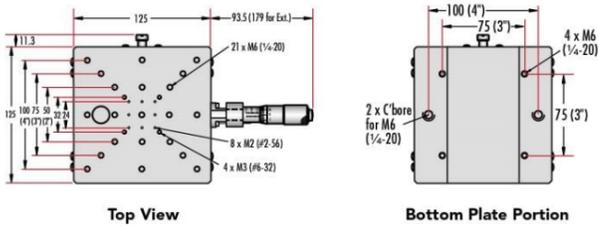

125mm Standard-Top Stages - Side Drive

