

[See all 6 Products in Family](#)

40mm Dia. x 100mm FL Uncoated, DCX N-K5 Lens



Stock #32-908 CLEARANCE 20+ In Stock

⊖ 1 ⊕ €19⁹⁵

ADD TO CART

Volume Pricing

Qty 1+	€19,95 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Double-Convex Lens **Type:**

Physical & Mechanical Properties

40.00 +0.00/-0.10 **Diameter (mm):**

<1 **Centering (arcmin):**

8.00 ±0.10 **Center Thickness CT (mm):**

4.09	Edge Thickness ET (mm):
39	Clear Aperture CA (mm):
Protective as needed	Bevel:
Optical Properties	
100.00 @ 587.6nm	Effective Focal Length EFL (mm):
97.34	Back Focal Length BFL (mm):
Uncoated	Coating:
N-K5	Substrate: <input type="checkbox"/>
40-20	Surface Quality:
1.5λ	Power (P-V) @ 632.8nm:
λ/4	Irregularity (P-V) @ 632.8nm:
±1	Focal Length Tolerance (%):
2.5	f#:
0.20	Numerical Aperture NA:
330 - 2500	Wavelength Range (nm):


Regulatory Compliance	
View	Certificate of Conformance:

Product Details

- N-K5 Substrate
- Various Anti-Reflection (AR) Coatings
- PCX and DCX Options Available

N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

Technical Information

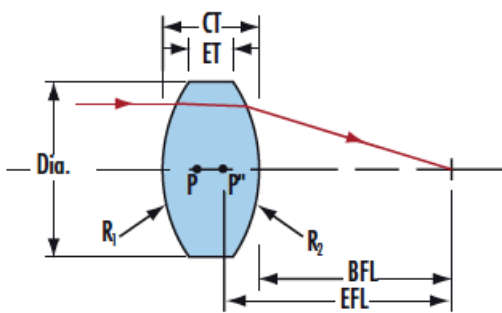

Compatible Mounts