


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

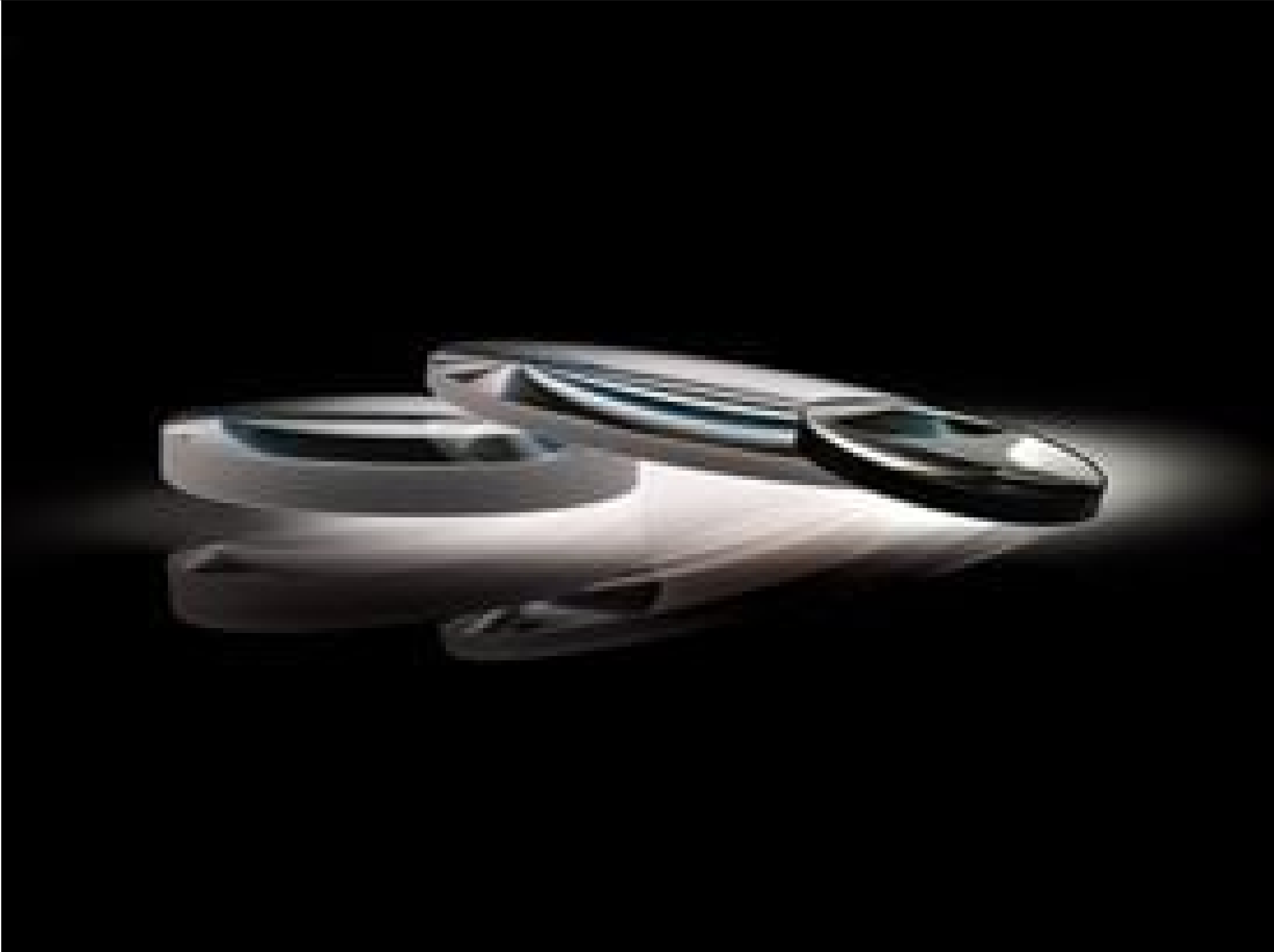

Stock #89-197-INK [CONTACT US](#)

[Other Coating Options](#)



1



€80,00

ADD TO CART

Qty 1-9

€80,00

Qty 10+

€72,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):

40.00 ±0.025

Back Focal Length BFL (mm):

117.67

|                                                                   |
|-------------------------------------------------------------------|
| <div>Effective Focal Length EFL (mm):<br/>120.00</div>            |
| <div>Coating:<br/>VIS-EXT (350-700nm)</div>                       |
| <div>Coating Specification:<br/>Ravg &lt;0.5% @ 350 - 700nm</div> |
| <div>Substrate: <div><div></div><div>N-BK7</div></div></div>      |
| <div>Surface Quality:<br/>40-20</div>                             |
| <div>Power (P-V) @ 632.8nm:<br/>1.5λ</div>                        |
| <div>Irregularity (P-V) @ 632.8nm:<br/>λ/4</div>                  |
| <div>Centering (arcmin):<br/>&lt;1</div>                          |
| <div>Bevel:<br/>Protective bevel as needed</div>                  |
| <div>Center Thickness CT (mm):<br/>7.00</div>                     |
| <div>Center Thickness Tolerance (mm):<br/>±0.10</div>             |
| <div>Edge Thickness ET (mm):<br/>3.72</div>                       |
| <div>Radius R<sub>1</sub>=R<sub>2</sub> (mm):<br/>122.83</div>    |
| <div>Clear Aperture CA (mm):<br/>39.00</div>                      |
| <div>f/#:<br/>3.00</div>                                          |
| <div>Focal Length Specification Wavelength (nm):<br/>587.6</div>  |
| <div>Focal Length Tolerance (%):<br/>±1</div>                     |
| <div>Numerical Aperture NA:<br/>0.17</div>                        |
| <div>Type:<br/>Double-Convex Lens</div>                           |
| <div>Wavelength Range (nm):<br/>350 - 700</div>                   |

## Regulatory Compliance

|                                                 |
|-------------------------------------------------|
| <div>RoHS:<br/>Compliant</div>                  |
| <div>Certificate of Conformance:<br/>View</div> |