


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 4.0mm Diameter X 5.0mm Length, N-BK7 Drum Lens

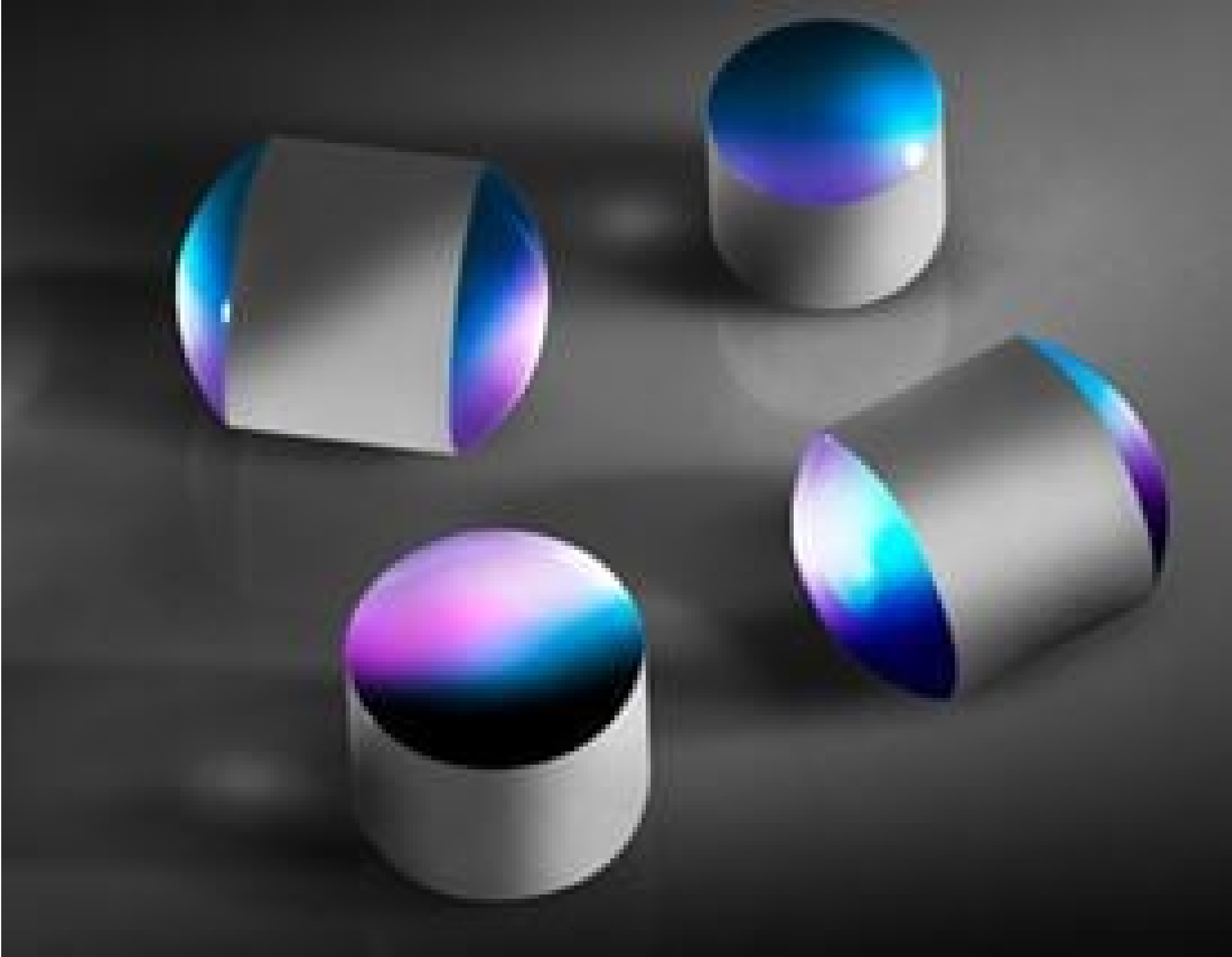

Stock #45-551 CLEARANCE ☐ In Stock

- 1 + **€19,95**

ADD TO CART

Qty 1+

€19,95

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
4.00

Substrate: ☐
[N-BK7](#)

Coating:
Uncoated

Type:
Drum Lens

Wavelength Range (nm): 350 - 2200
Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): $+0/-1.5$
Surface Quality: 40-20
Diameter Tolerance (μm): $+0/-50$

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View