

TECHSPEC<sup>®</sup> 40mm, Side Drive, Standard Top, English Stage



40mm, Side Drive, Solid Top Stage

Stock **#66-405** **3 In Stock**

-

1

+

€391<sup>00</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-2        | €391,00 each                  |
| Qty 3+         | €341,40 each                  |
| Need More?     | <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

English

Type:

Physical & Mechanical Properties

Linear (X)

Type of Movement:

Crossed Roller Bearing

Guide System:




30mm Standard-Top Stages - Center Drive



30mm Standard-Top Stages - Side Drive



40mm Standard-Top Stages - Center Drive

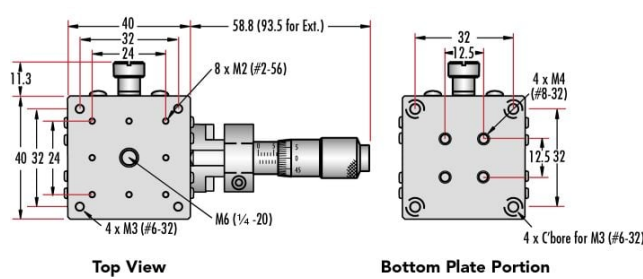


40mm Standard-Top Stages - Side Drive



70mm Standard-Top Stages - Center Drive



70mm Standard-Top Stages - Side Drive

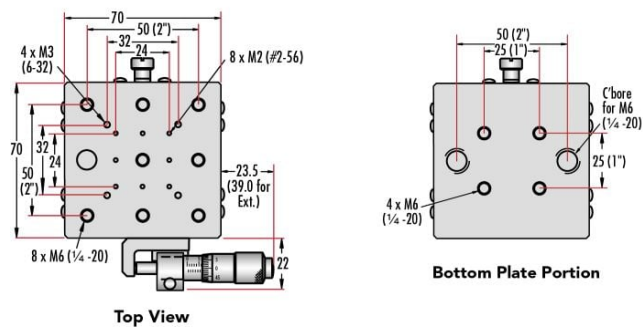

125mm Standard-Top Stages - Center Drive



125mm Standard-Top Stages - Side Drive

