


49mm Diameter Float Glass Window

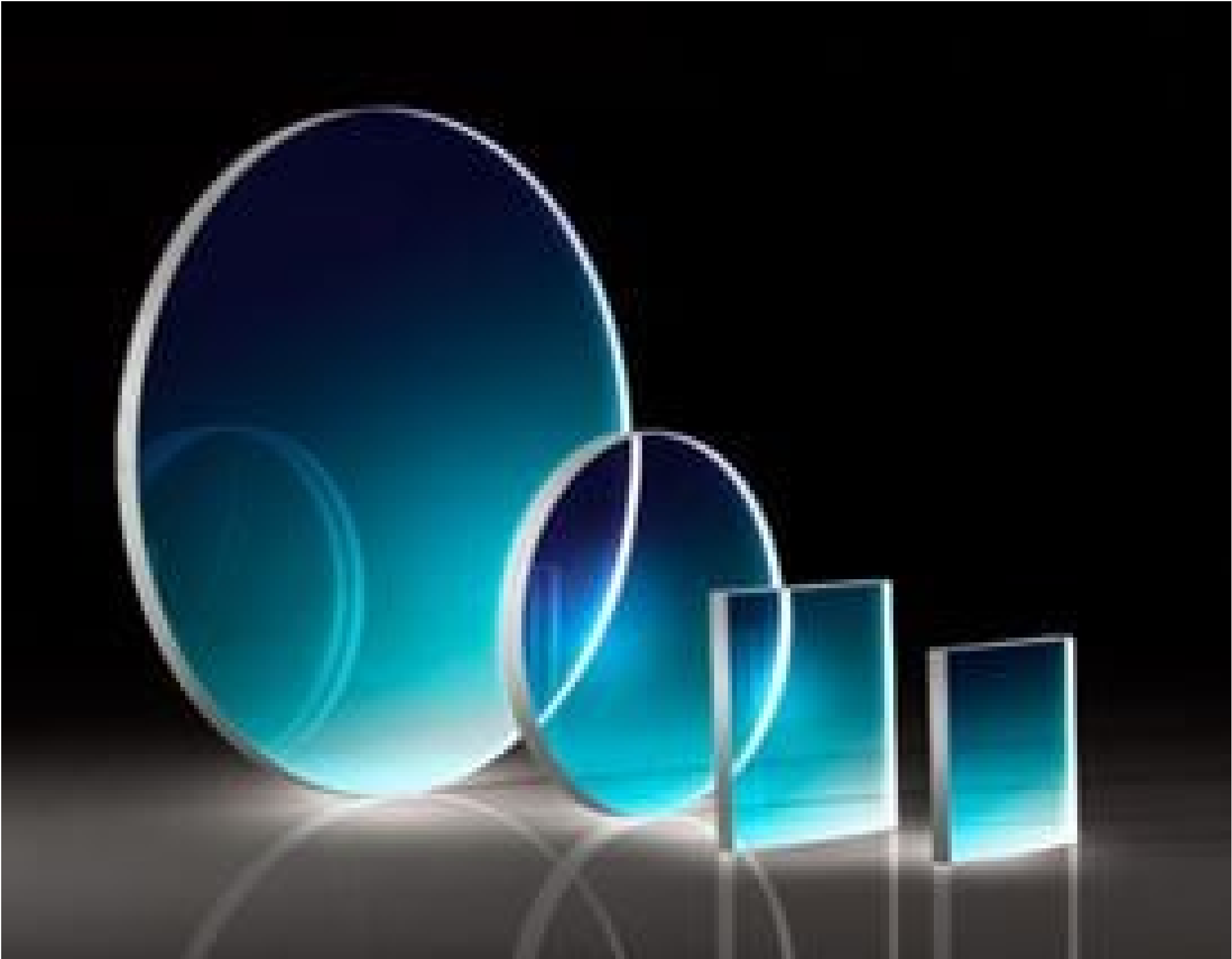

Stock **#30-971** **16 In Stock**

-

1

+

€25^{.50}

ADD TO CART

Volume Pricing	
Qty 1-5	€25,50 each
Qty 6-49	€23,00 each
Qty 50-99	€22,00 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Protective Window

Type:

Physical & Mechanical Properties

49.00

Diameter (mm):

1.50

Thickness (mm):

Fine Ground	Edges:
Optical Properties	
Uncoated	Coating:
Float Glass	Substrate: ☐
80-50	Surface Quality:
350 - 2000	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts