


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

50.8 X 50.8 X 3mm High Efficiency window

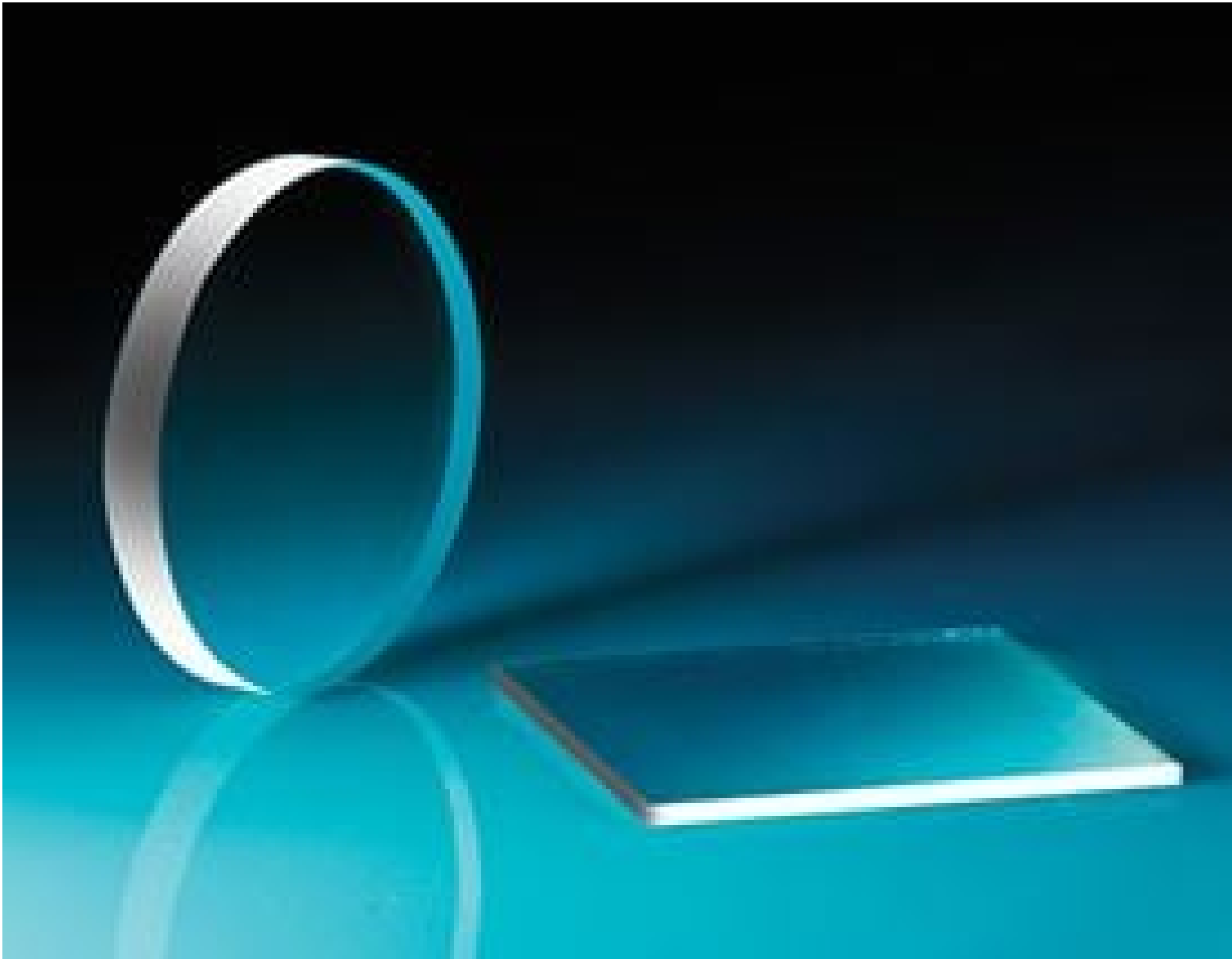

Stock #46-099 3-4 DAYS



1



€22,50

ADD TO CART

Qty 1-5

€22,50

Qty 6+

€18,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm): 45.72 x 45.72
Dimensions (mm): 50.80 x 50.80
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: R _{avg} ≤0.5% @ 425 - 700nm
Edges: Seamed
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700
Length (mm): 50.80
Width (mm): 50.80

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant