


TECHSPEC® 50.8mm Dia. Silver, Precision Broadband Laser Mirror

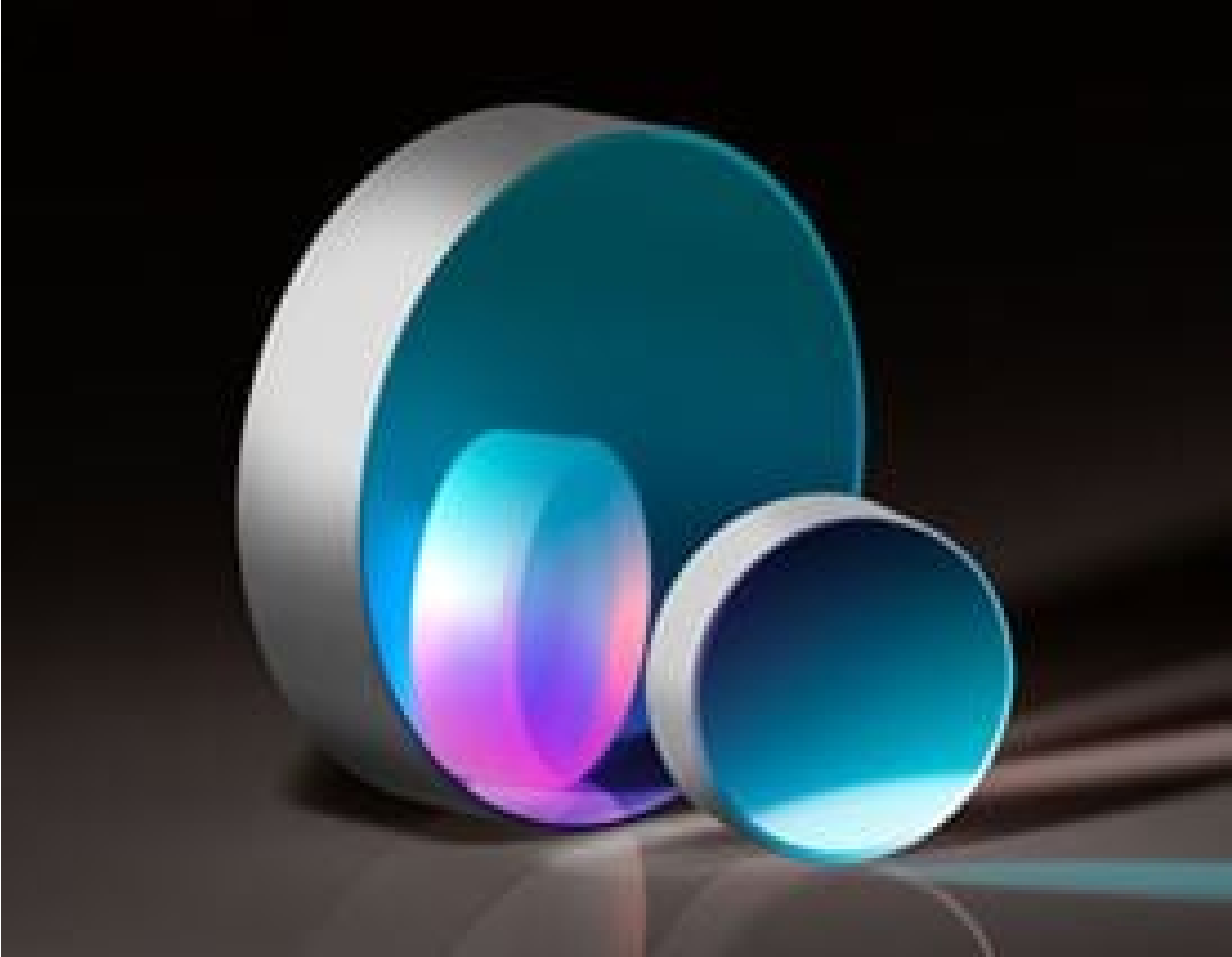

Stock **#48-017** ☐ In Stock

- 1 + **€370,00**

ADD TO CART

Qty 1-5
€370,00
Qty 6+
€327,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability: ML-M-13508-C
Back Surface: Ground
Coating Specification: R_{avg} >99% @ 0.45 - 12.0μm
Wavelength Range (nm): 450 - 12000
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Dielectric
Coating: Protected Silver (450-12000nm)
Diameter (mm): 50.80 +0.0/-0.2
Thickness (mm): 12.50 ±0.3
Angle of Incidence (°): 0-45
Substrate:  BOROFLOAT®
Note: Optical Power: λ/10
Damage Threshold, By Design:  0.5 J/cm² @ 10ns

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View