


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

50µm Emitter, 500µm Pitch Slow Axis Collimator

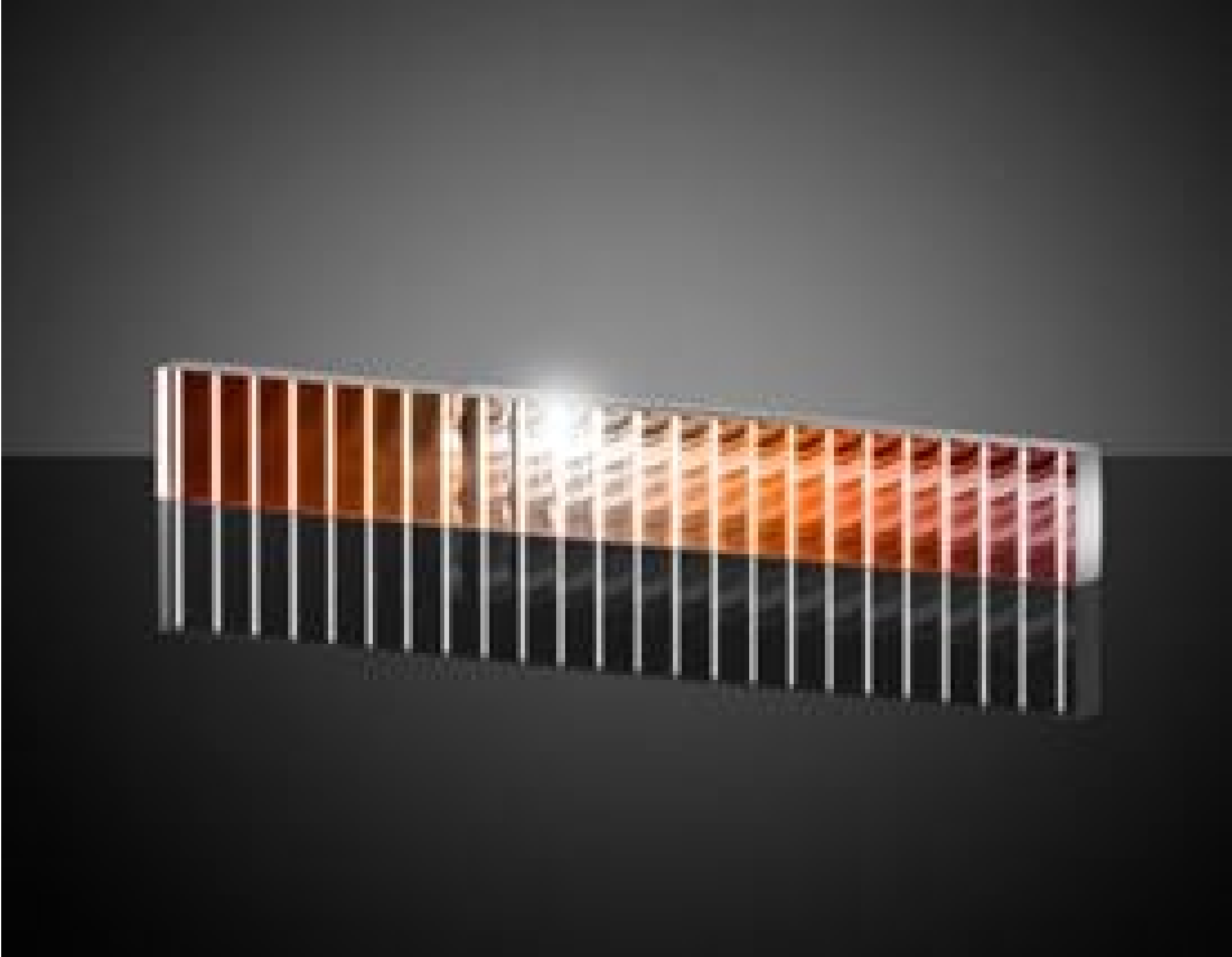

Slow Axis Collimators

Stock #88-403 3-4 DAYS



1



€184,00

ADD TO CART

Qty 1-10

€184,00

Qty 11+

€162,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Effective Focal Length EFL (mm):
4.25

Substrate:
[S-TIH53](#)

f/#:
10.00

Numerical Aperture NA: 0.05
Coating: BBAR (790-990nm)
Type: Beam Shaper
Wavelength Range (nm): 790 - 990
Back Focal Length BFL (mm): 3.70
Clear Aperture CA (mm): 11.0 x 1.4
Coating Specification: R _{avg} <1.0% @ 790 - 990nm
Emitter Size (µm): 50.00
Height (mm): 1.50
Height Tolerance (mm): 0.05
Length (mm): 12.00
Length Tolerance (mm): ±0.05
Pitch (µm): 500.00
Surface Accuracy: λ/4
Transmission (%): >99
Width (mm): 1.00
Width Tolerance (mm): 0.05
Divergence 1/e² (mrad): 15.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View