


TECHSPEC® 50mm Dia. Laser Mirror Substrate

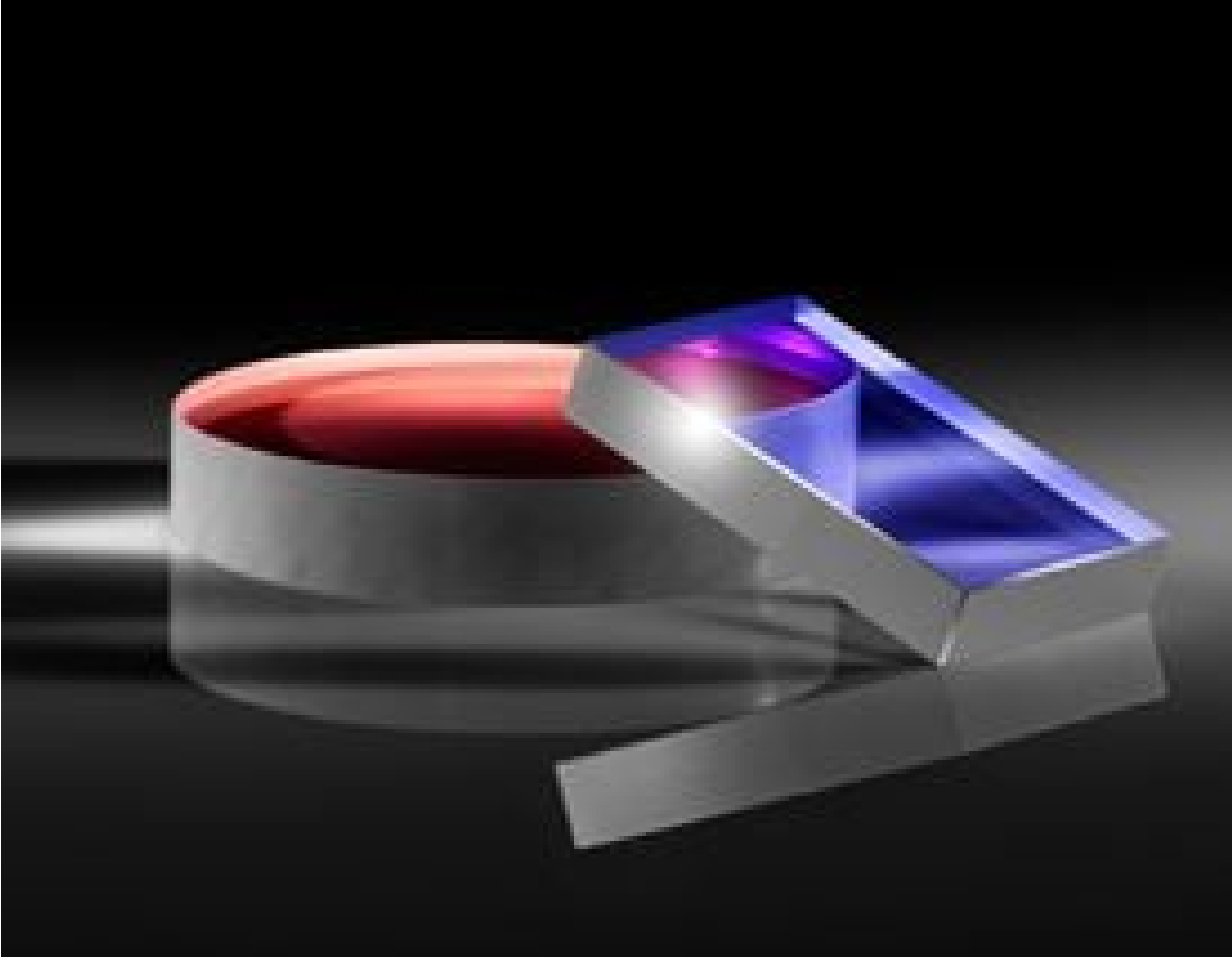

TECHSPEC® Laser Mirror Substrates

Stock **#47-155** 3-4 DAYS



1



€153,00

ADD TO CART

Qty 1-10

€153,00

Qty 11+

€135,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Quality:
10-5

Type:
Laser Mirror Substrate

Parallelism (arcmin):
<3

Clear Aperture (%) : 90
Back Surface : Ground
Surface Flatness (P-V) : λ/10
Coating : Uncoated
Diameter (mm) : 50.00 +0.00/-0.20
Thickness (mm) : 10.00 ±0.20
Substrate : Fused Silica (Corning 7980)

Regulatory Compliance

RoHS 2015 : Compliant
Reach 211 : Compliant
Certificate of Conformance : View