


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

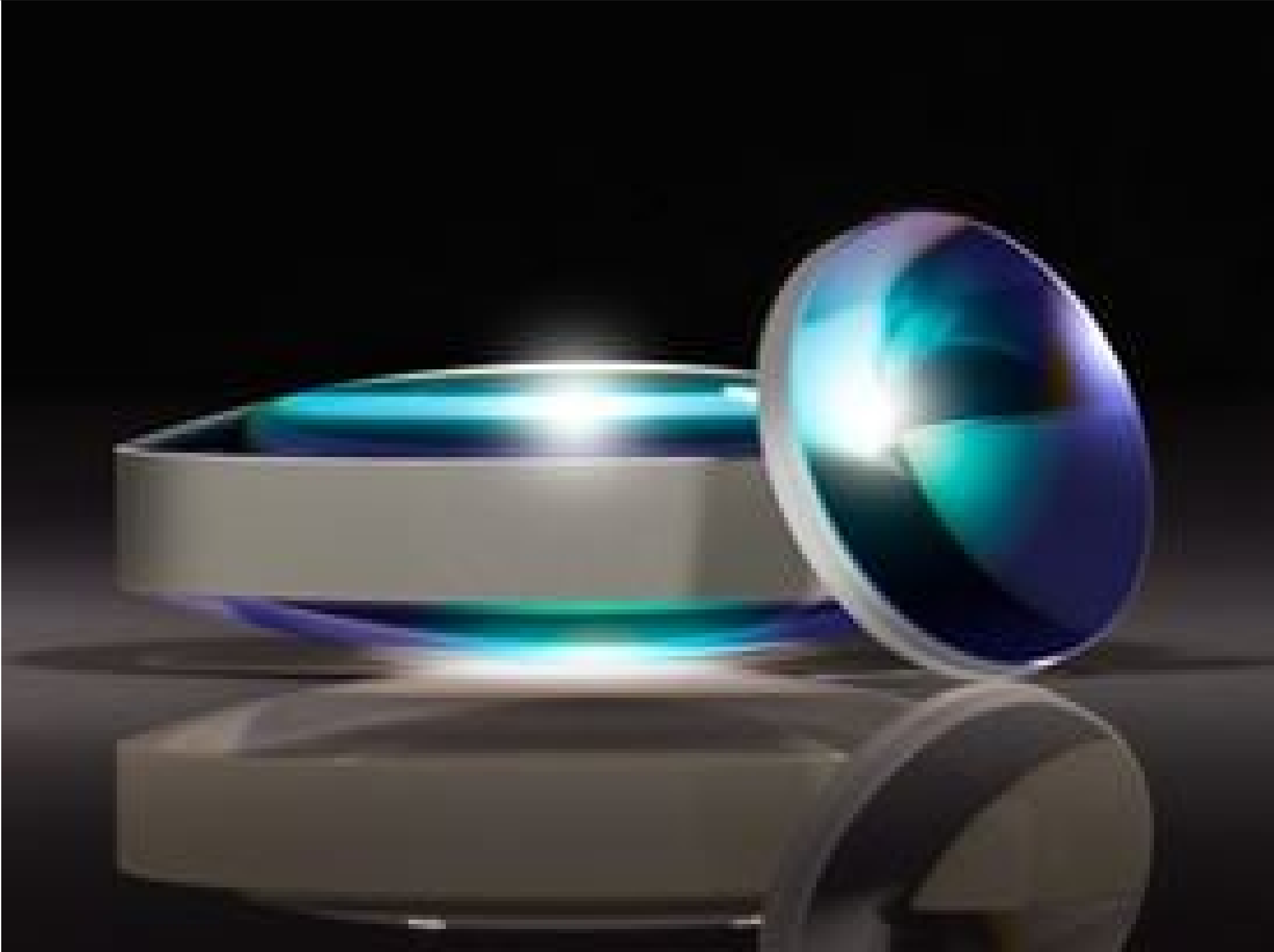

Stock #18-423 3-4 DAYS



1



€720,00

ADD TO CART

Qty 1-5

€720,00

Qty 6+

€576,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
50.00 +0.0/-0.025

Effective Focal Length EFL (mm):
50.00

Back Focal Length BFL (mm):
44.04

Substrate: N-BK7
Aspheric Design Wavelength (nm): 587.6
Asphere Figure Error, RMS @ 632.8nm: 0.4λ RMS and 2λ PV
Coating: Uncoated
Centering (arcmin): 3
Surface Quality: 40-20
Clear Aperture CA (mm): 45
Edge Thickness ET (mm): 5
Center Thickness CT (mm): 17.00 ±0.1
f#: 1.00
Bevel: None
Type: Aspheric Lens
Wavelength Range (nm): 330 - 2400
Radius R₁=R₂ (mm): 48.6
Power (diopters): 20.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View