


50mm Travel, Metric Micrometer, Thru-Hole Ball Bearing Stage

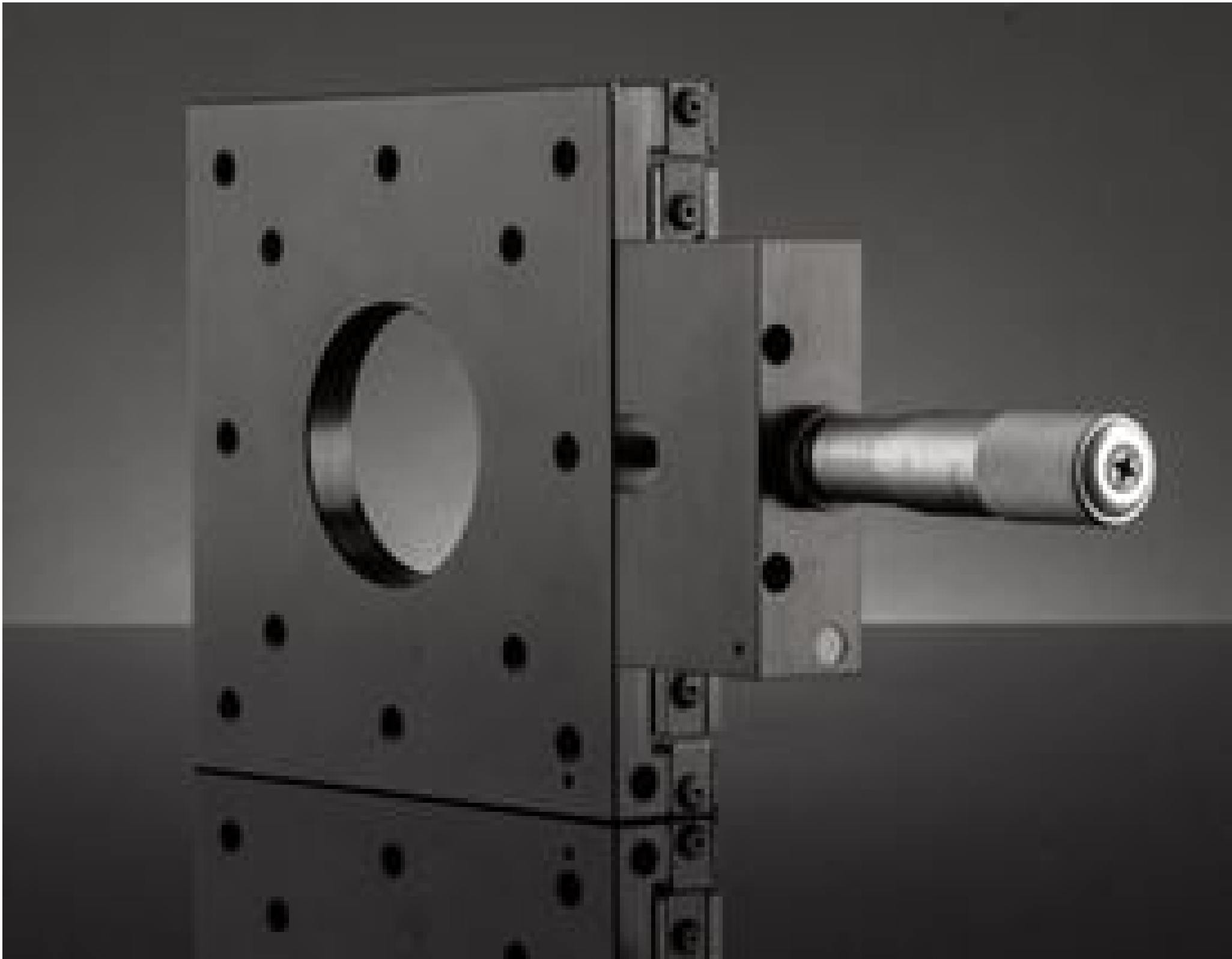

5" Center drive stage

Stock #38-180 3-4 DAYS

- 1 + **€1.108,00**

ADD TO CART

Qty 1+

€1.108,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Ball Bearing

Type of Drive:
Metric Micrometer

Drive Orientation:
Center Drive

Type:

English
Stage Size (mm): 127 x 127
Travel (mm): 50
Construction: Aluminium Stage
Graduation (mm): 0.01
Height (inches): 1.00
Height (mm): 25.4
Load Capacity, Normal (lbs): 105
Note: Thru-Hole
Stage Size (inches): 5.00 x 5.00
Straight Line Accuracy (inches): 0.00008/inch of travel
Weight (lbs): 2.7
Thrust Capacity, T_a (lbs): 30
Thrust Capacity, T_b (lbs): 2.5

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View