


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

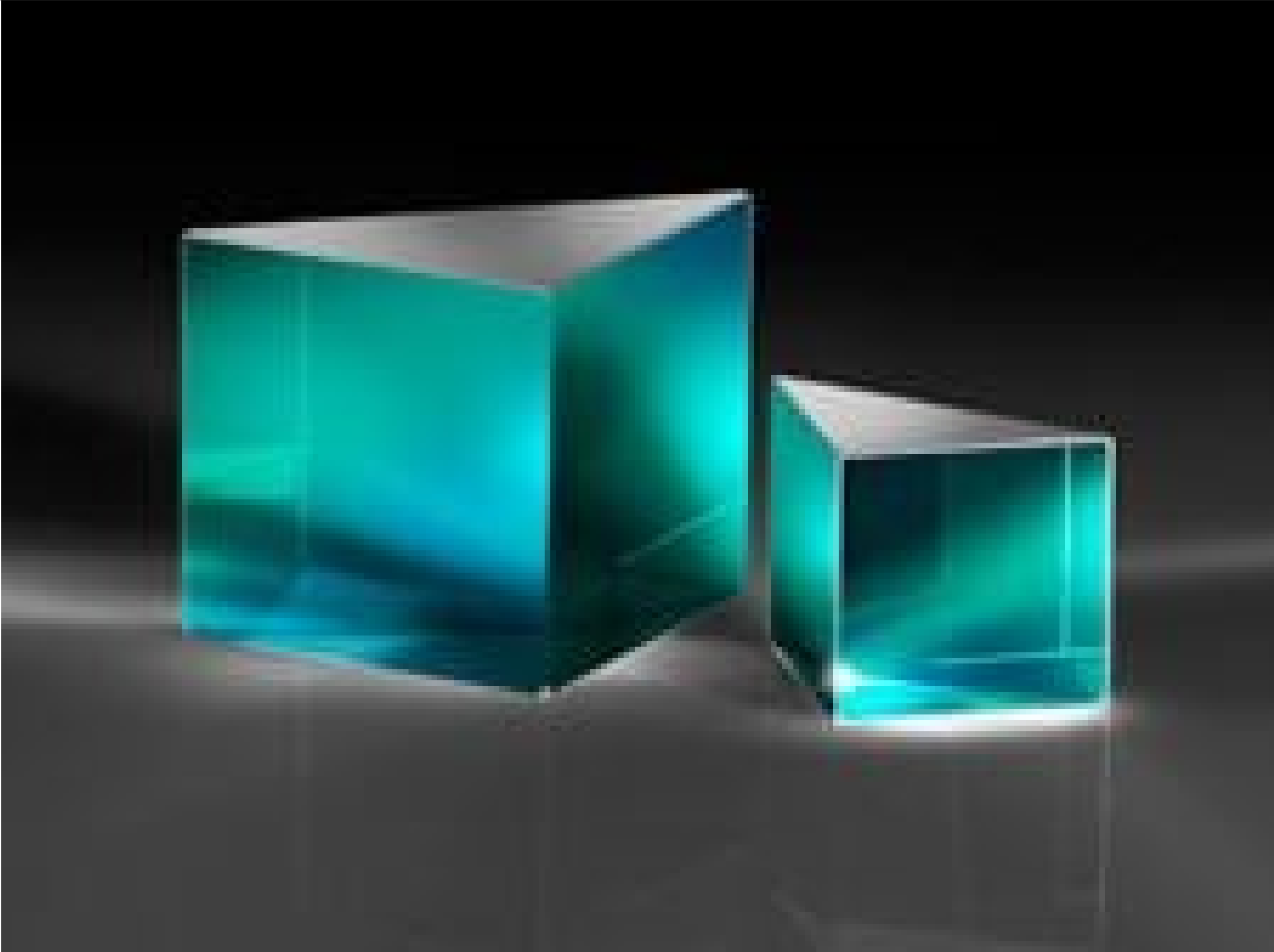

Stock #84-512 3-4 DAYS



1



€258,00

ADD TO CART

Qty 1-5

€258,00

Qty 6+

€206,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle Tolerance (arcsec):
±15

Coating:
VS 0° (425-675nm)

Substrate: ☐
[N-BK7](#)

Surface Quality: 40-20
Type: Right Angle Prism
Dimensional Tolerance (mm): +0.00/-0.10
Bevel: Protective bevel as needed
Clear Aperture (%): 90
Length of Hypotenuse (mm): 70.70
Length of Legs (mm): 50.00
Image Orientation: Left-Handed
Note: Coating on Entrance/Exit Faces
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 90
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8
Damage Threshold, Reference: ☐ Entrance/Exit Faces: 5 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant