


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

5.5" Diameter, Plastic Optical window

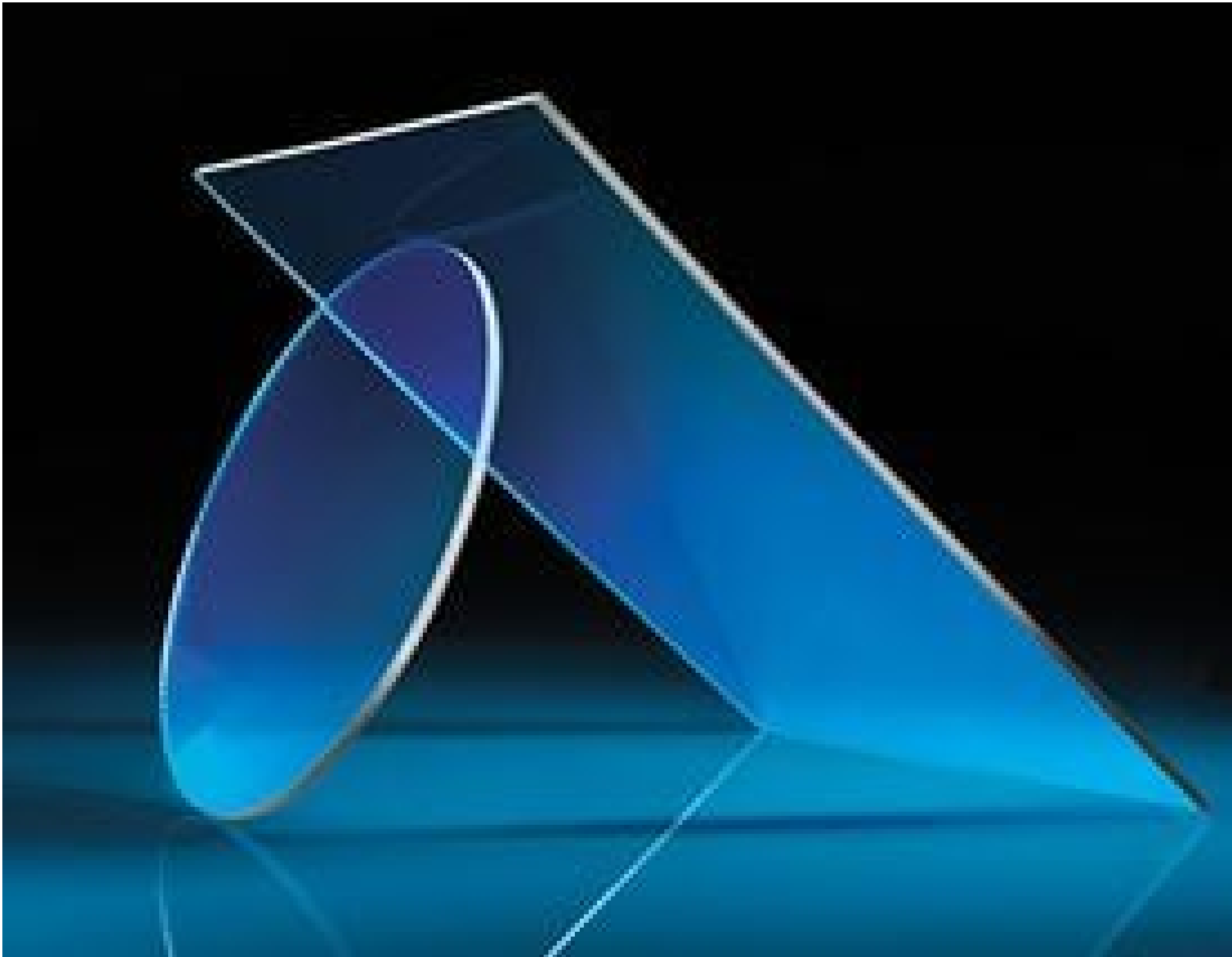

Stock #43-926 CLEARANCE ☐ In Stock

-

1

+

 €29,95

ADD TO CART

Qty 1+

€29,95

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
57.00

Diameter (mm):
139.70 ±0.3

Diameter (inches):
5.5

Thickness (mm):
1.50 ±0.15

Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View