


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

5.7 mm² DUV Photodiode with Ceramic Housing

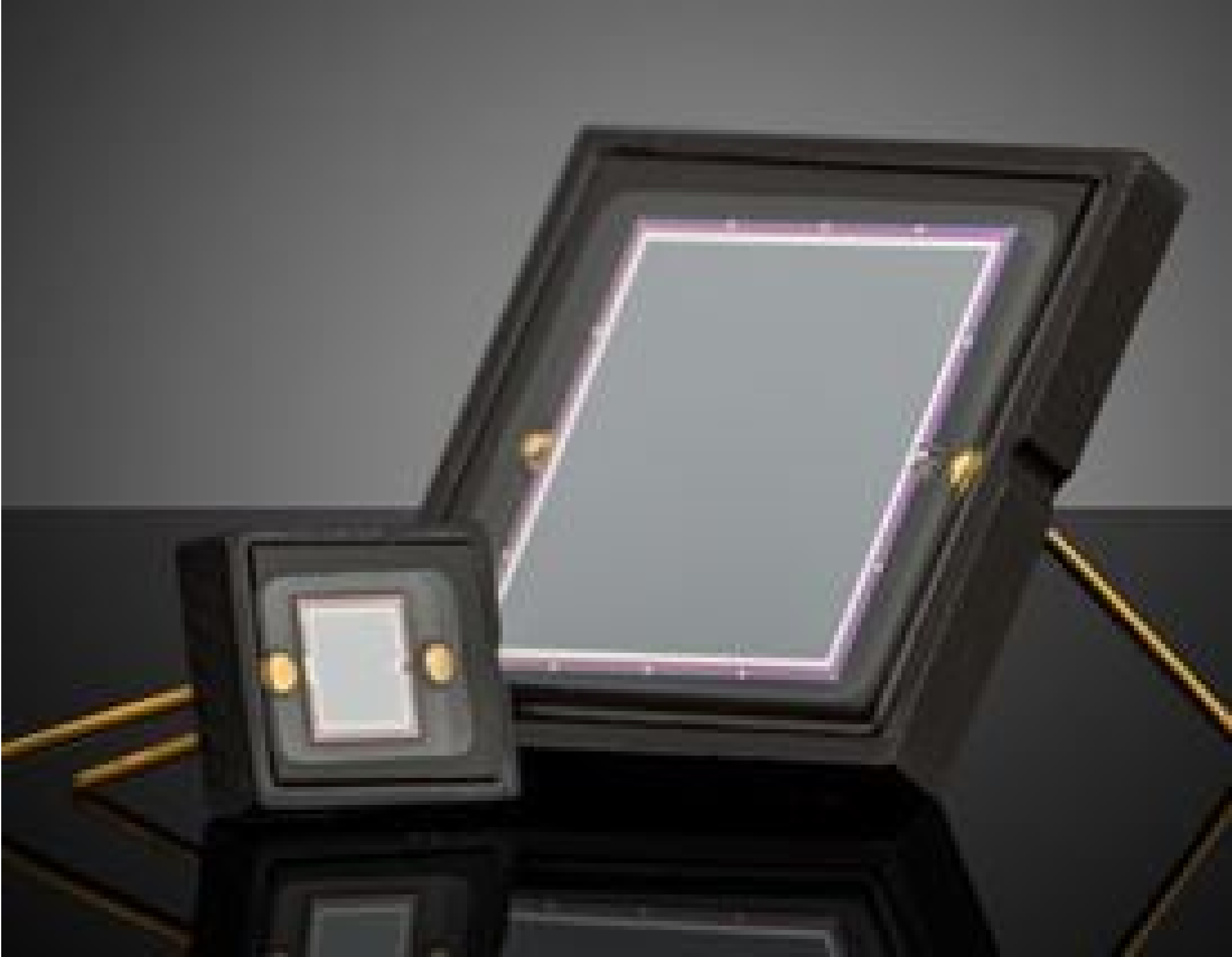

DUV Photodiodes

Stock **#84-982** 3-4 DAYS



1



€95,00

ADD TO CART

Qty 1-4

€95,00

Qty 5+

€84,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Operating Temperature (°C):
-20 to +60

Size of Active Area (mm):
2.4 x2.4

Storage Temperature (°C):
-20 to +80

Rise Time (μs): 0.2 @ 0 V, 1 kΩ
Responsivity @ 980nm (AW): 0.5
Shunt Resistance @ V=-10mV (GΩ): Minimum: 0.3 Typical: 1
Responsivity @ 633nm (AW): 0.34
Responsivity @ 200nm (AW): 0.12
Capacitance @ V_R=0V (pF): 65.00
Active Area (mm²): 5.7
Noise Equivalent Power NEP (W/ Hz^{1/2}): 3.6 x 10 ⁻¹⁴ @ 0 V, 200nm
Maximum Reverse Voltage (V): 5.00
Connector: Ceramic
Peak Response Wavelength (nm): 980.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View