


5mW, 635nm Laser Bat Power ZAT, 5° X-Hair

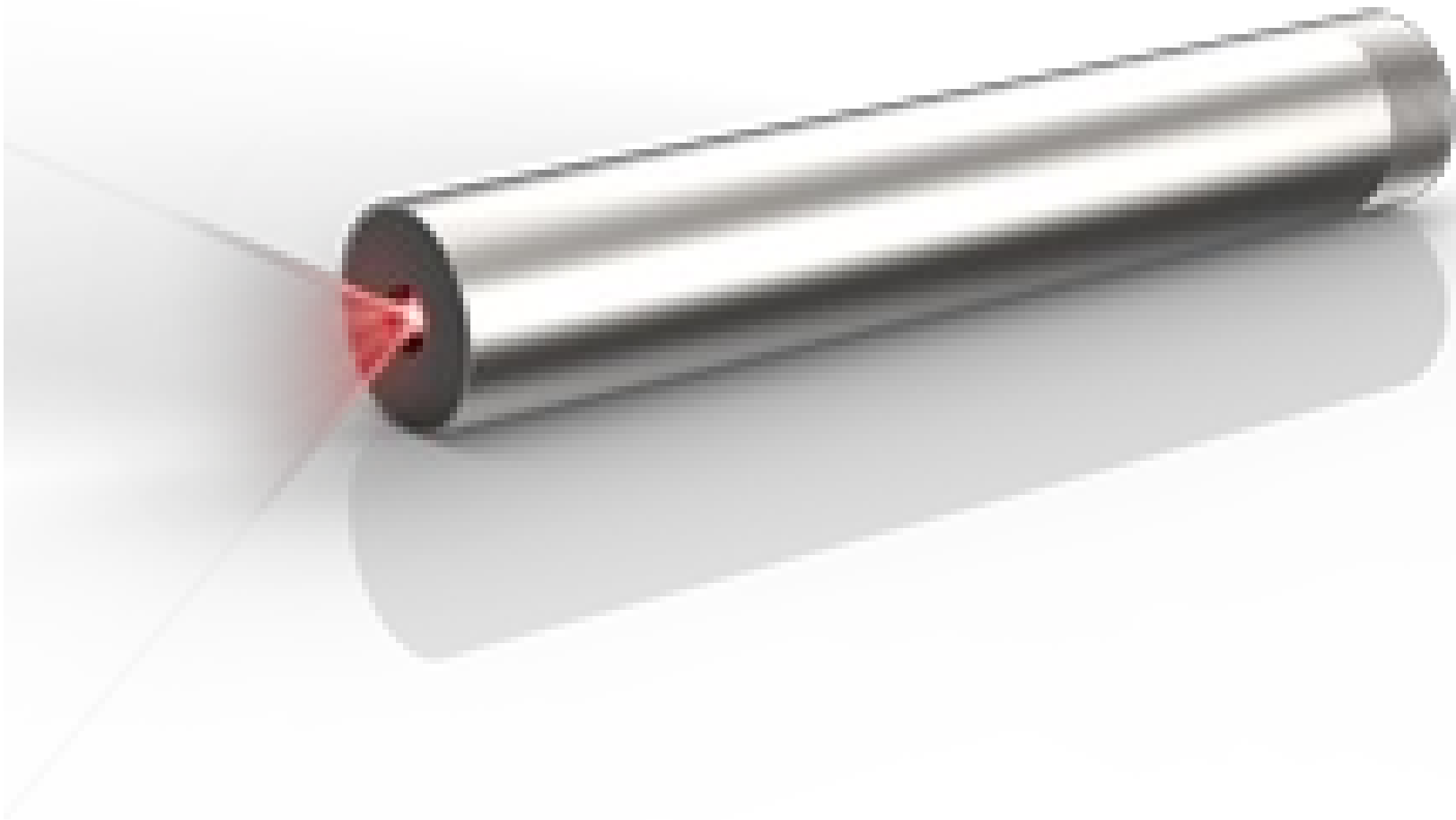

Stock **#19-539** 1 In Stock

-

1

+

€322^{.00}

ADD TO CART

Volume Pricing	
Qty 1-9	€322,00 each
Qty 10+	€289,00 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes



General

Style: Crosshair

2M Laser Class - CDRH:

Physical & Mechanical Properties

162 **Weight (g):**

Length (mm): 124.00

Optical Properties

Wavelength (nm): 635.00

Color: Red

5.00 Fan Angle (°):

Up to 1,200mm **Focus Range (mm):**

Electrical

5 **Output Power (mW):**

Hardware & Interface Connectivity

1 AA Battery (Not Included) **Power Requirement:**

Free Space

Environmental & Durability Factors

IP40 **Environmental Rating:**

Regulatory Compliance

Certificate of Conformance:

Product Details

- Bright Red 635nm Wavelength
- Line, Crosshair, or Dot Projection
- Battery Powered Operation with a Fixed Focus
- Sturdy, Metal Housing

Z-Laser ZAT Battery Powered Lasers are ideal for positioning and alignment applications. Their battery powered design provides maneuverability by removing the need for a fixed power supply. IP40 rated, shock proof, and vibration proof with a sturdy, metal housing makes these lasers excellent for harsh environments and repeated use. Z-Laser ZAT Battery Powered Lasers are suitable for use in industrial environments such as Automotive, Paper, Wood, Ceramic, and Metal. Available with 1 or 5mW output powers, the lasers utilize one AA battery (not included) ensuring easy maintenance and an extended lifetime.