


5mW, 635nm Laser Bat Power ZAT, 60° X-Hair (Recertified 05-P)

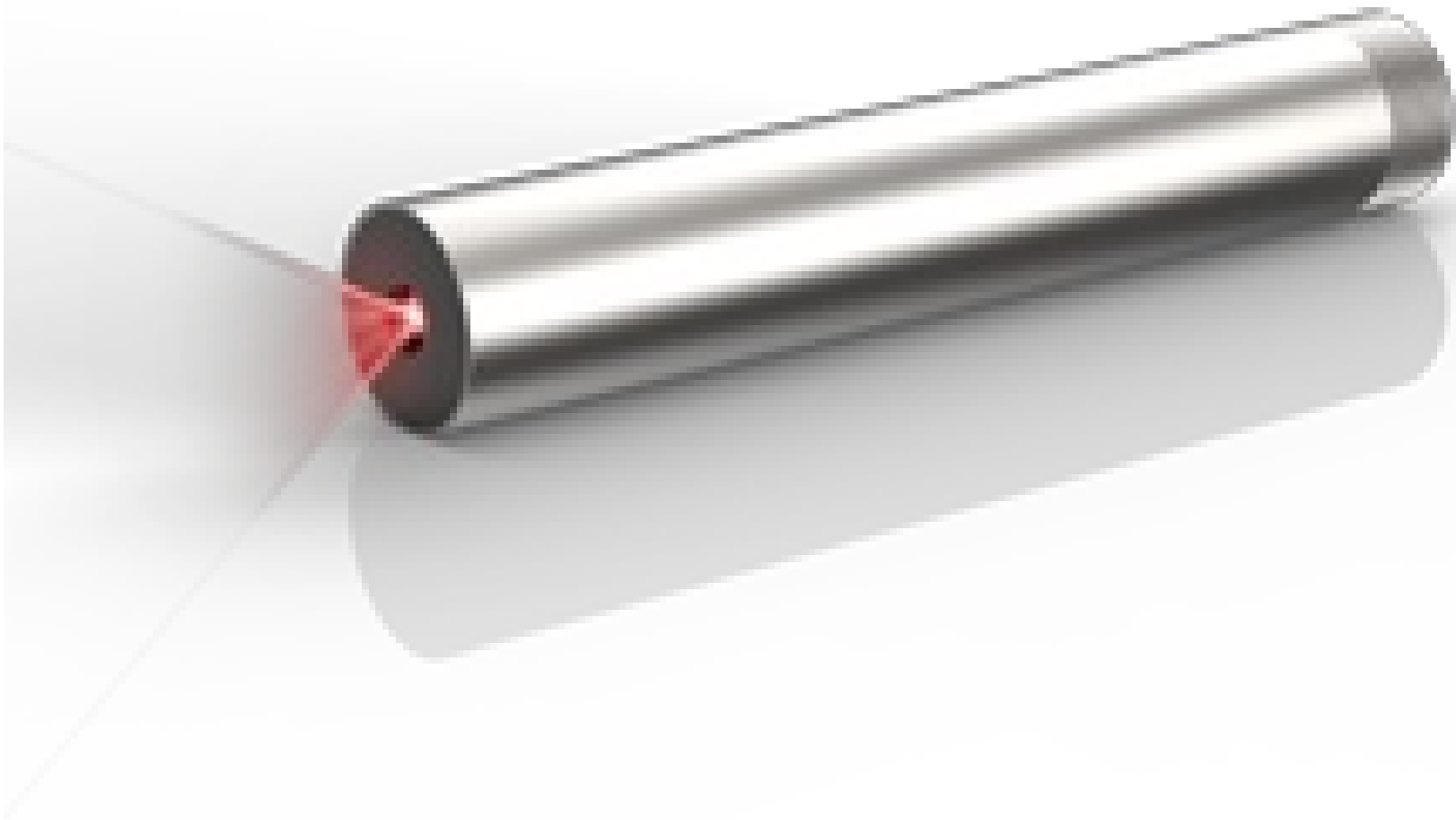

Stock #19-540-RCD-05P RECERTIFIED 1 In Stock

-

1

+

€298⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	€298,00 each
Need More?	Request Quote

ⓘ

 Prices shown are exclusive of VAT/local taxes



General	
Crosshair	Style:
1M	Laser Class - CDRH:
Physical & Mechanical Properties	
162	Weight (g):
124.00	Length (mm):
Optical Properties	
635.00	Wavelength (nm):
Red	Color:
60.00	Fan Angle (°):
Up to 1,500mm	Focus Range (mm):
Electrical	
5	Output Power (mW):
Hardware & Interface Connectivity	
1 AA Battery (Not Included)	Power Requirement:
Free Space	Output Type:
Environmental & Durability Factors	
IP40	Environmental Rating:
Regulatory Compliance	
View	Certificate of Conformance:

Product Details

- Bright Red 635nm Wavelength
- Line, Crosshair, or Dot Projection
- Battery Powered Operation with a Fixed Focus
- Sturdy, Metal Housing

Z-Laser ZAT Battery Powered Lasers are ideal for positioning and alignment applications. Their battery powered design provides maneuverability by removing the need for a fixed power supply. IP40 rated, shock proof, and vibration proof with a sturdy, metal housing makes these lasers excellent for harsh environments and repeated use. Z-Laser ZAT Battery Powered Lasers are suitable for use in industrial environments such as Automotive, Paper, Wood, Ceramic, and Metal. Available with 1 or 5mW output powers, the lasers utilize one AA battery (not included) ensuring easy maintenance and an extended lifetime.