


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 60 X 85mm Enhanced Aluminum, 4-6λ Mirror

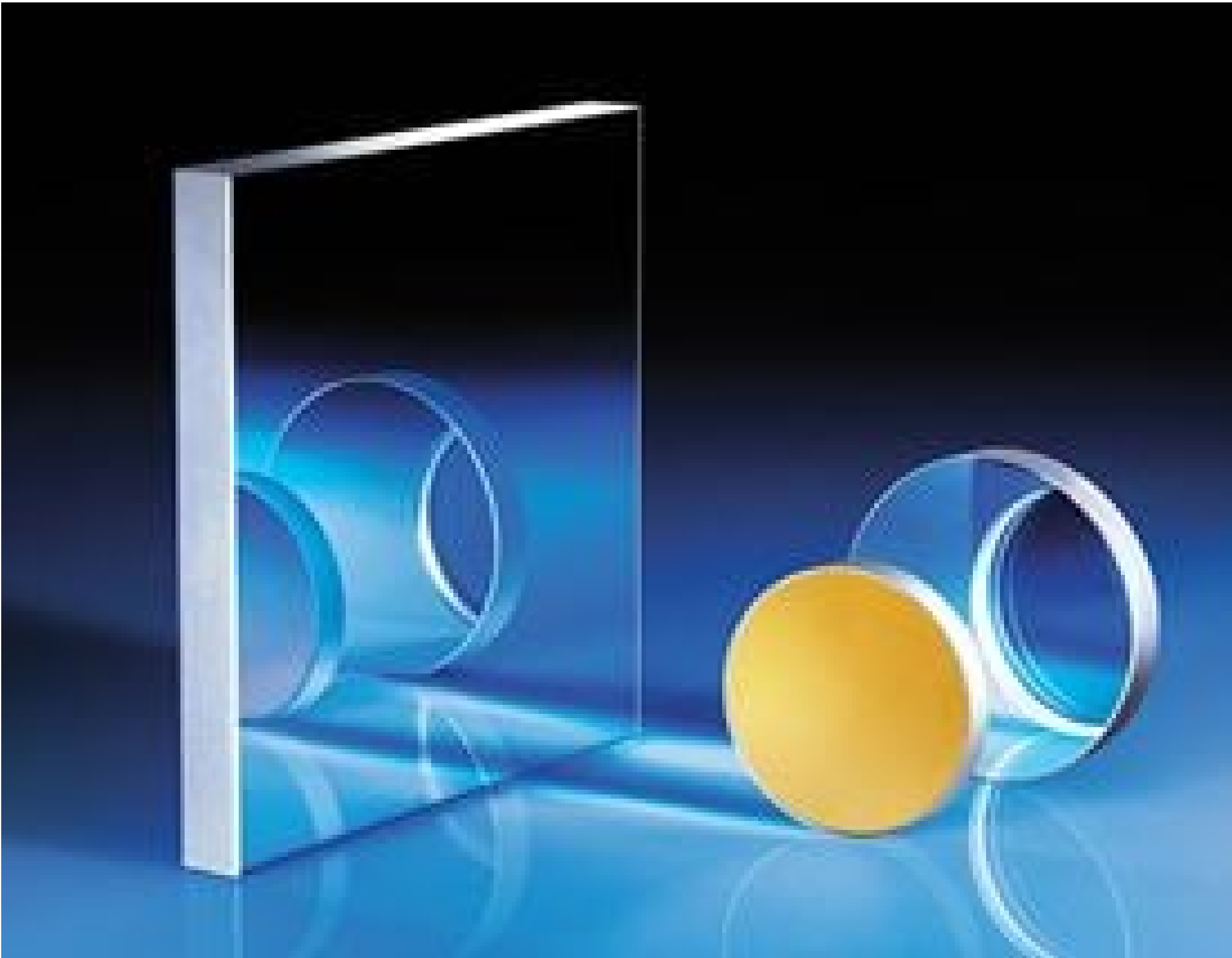

Stock #64-410 ☒ In Stock



1



€46,50

ADD TO CART

Qty 1-5

€46,50

Qty 6+

€36,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Flatness (P-V):
4 - 6λ

Substrate: ☐
Float Glass

Surface Quality:
60-40

Dimensions (mm):

60.0 x 85.0
Dimensional Tolerance (mm): ±0.25
Coating Specification: R _{avg} ≥95% @ 450 - 650nm @ 45°
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture CA (mm): 57.00 x 80.75
Edges: Seamed, 0.5mm Maximum Edge Chip
Thickness (mm): 3.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 85.00
Width (mm): 60.00
Damage Threshold, By Design: ☐ 0.2 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant