


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 75mm Dia Enhanced Aluminum, λ/20 Mirror

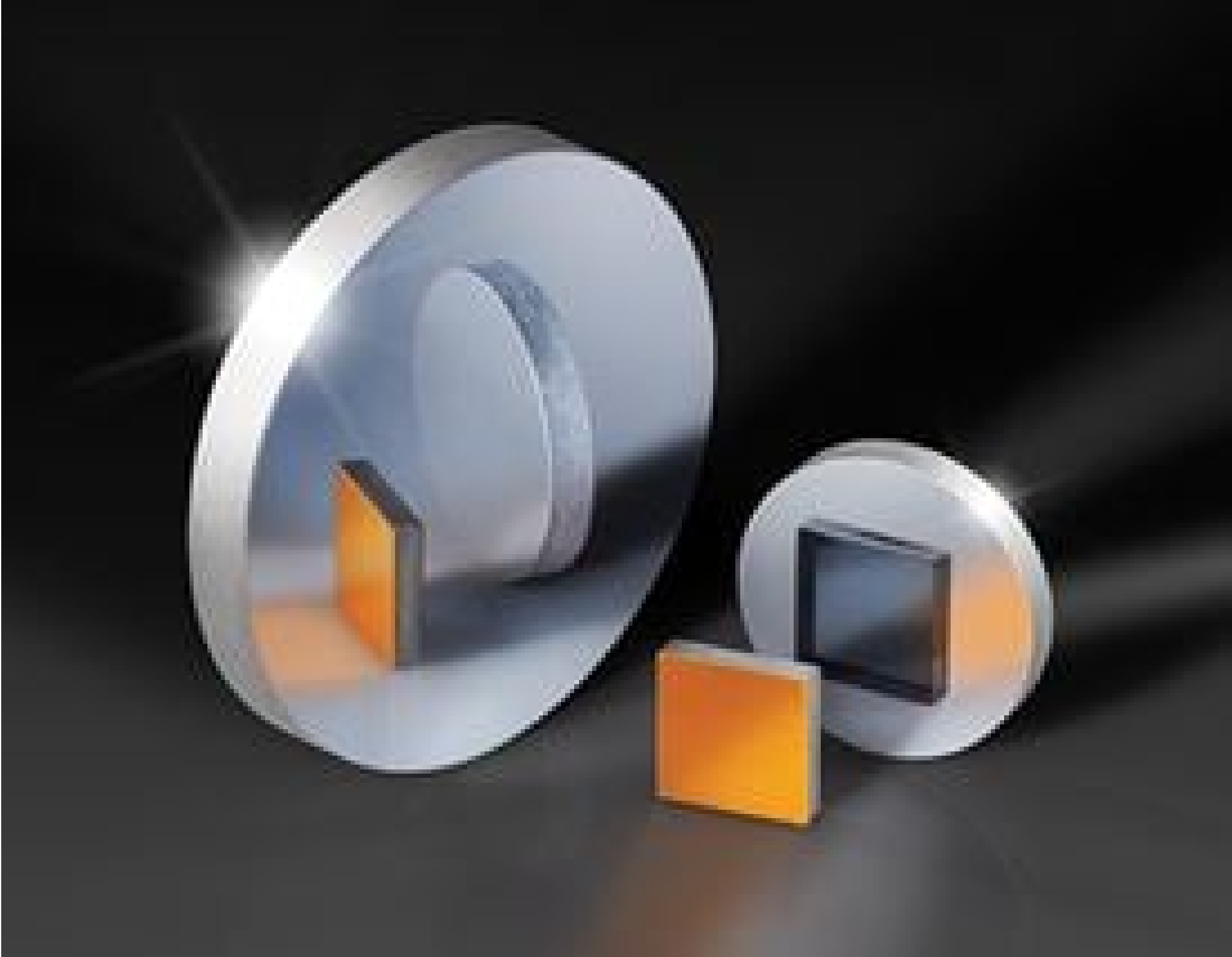

Stock #34-368 3-4 DAYS

1 €499,00

ADD TO CART

Qty 1-5

€499,00

Qty 6+

€399,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
75.00 +0.0/-0.20

Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Back Surface: Commercial Polish
Surface Quality: 20-10
Coating Specification: R _{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 7.50 ±0.20
Type: Flat Mirror
Wavelength Range (nm): 450 - 650

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant