


80 Grooves/mm, 12.7mm Sq, Transmission Grating Beamsplitter

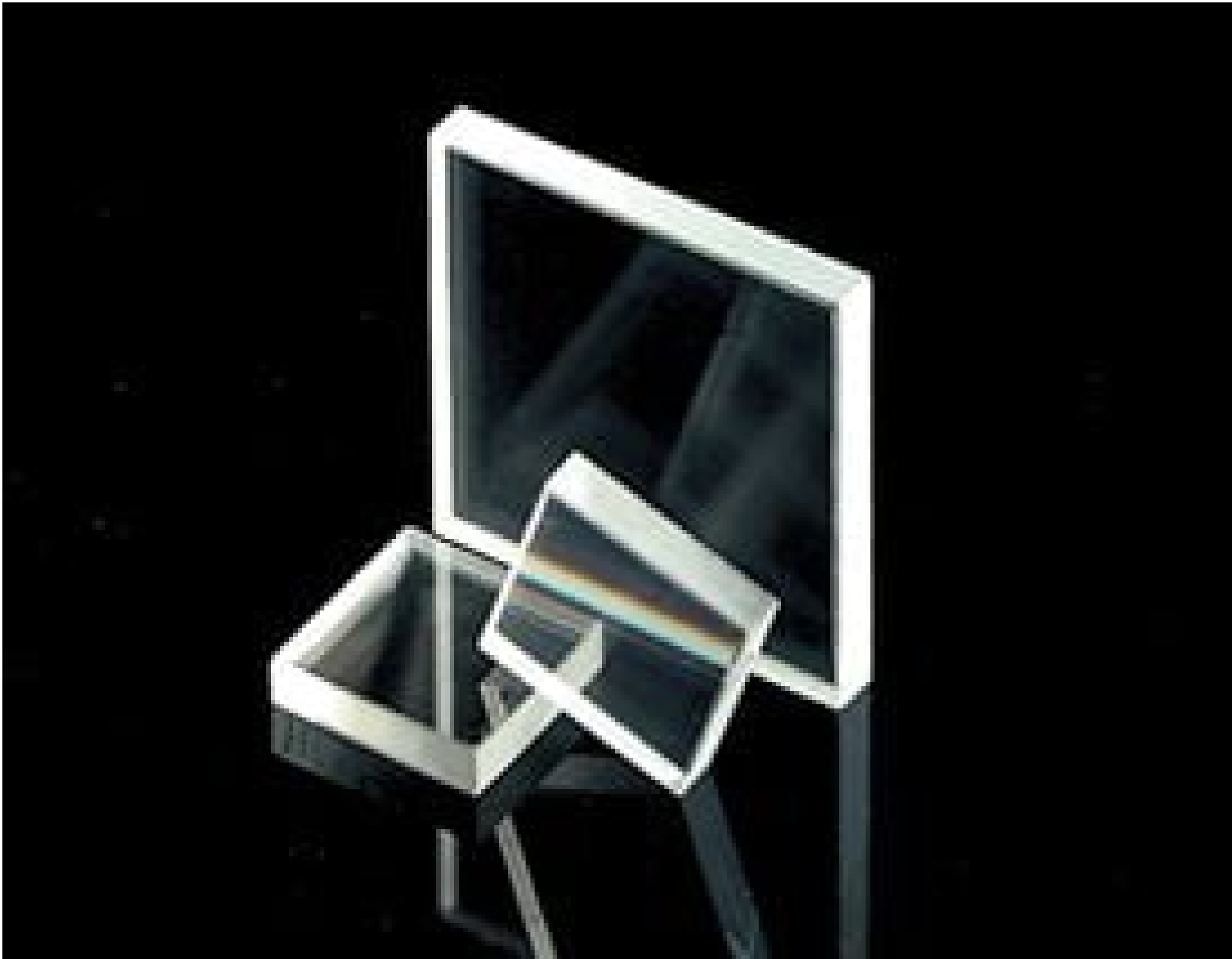

Stock **#46-069** 3-4 DAYS

- 1 + **€130,00**

ADD TO CART

Qty 1-10
€130,00
Qty 11+
€117,00
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
80

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
12.7 x 12.7 ±0.5

Construction: Blazed Grating
Length (mm): 12.70
Substrate: ☐ E270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 12.70

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
