


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

830 Grooves, 12.7 mm Square, 800nm NIR Ruled Grating

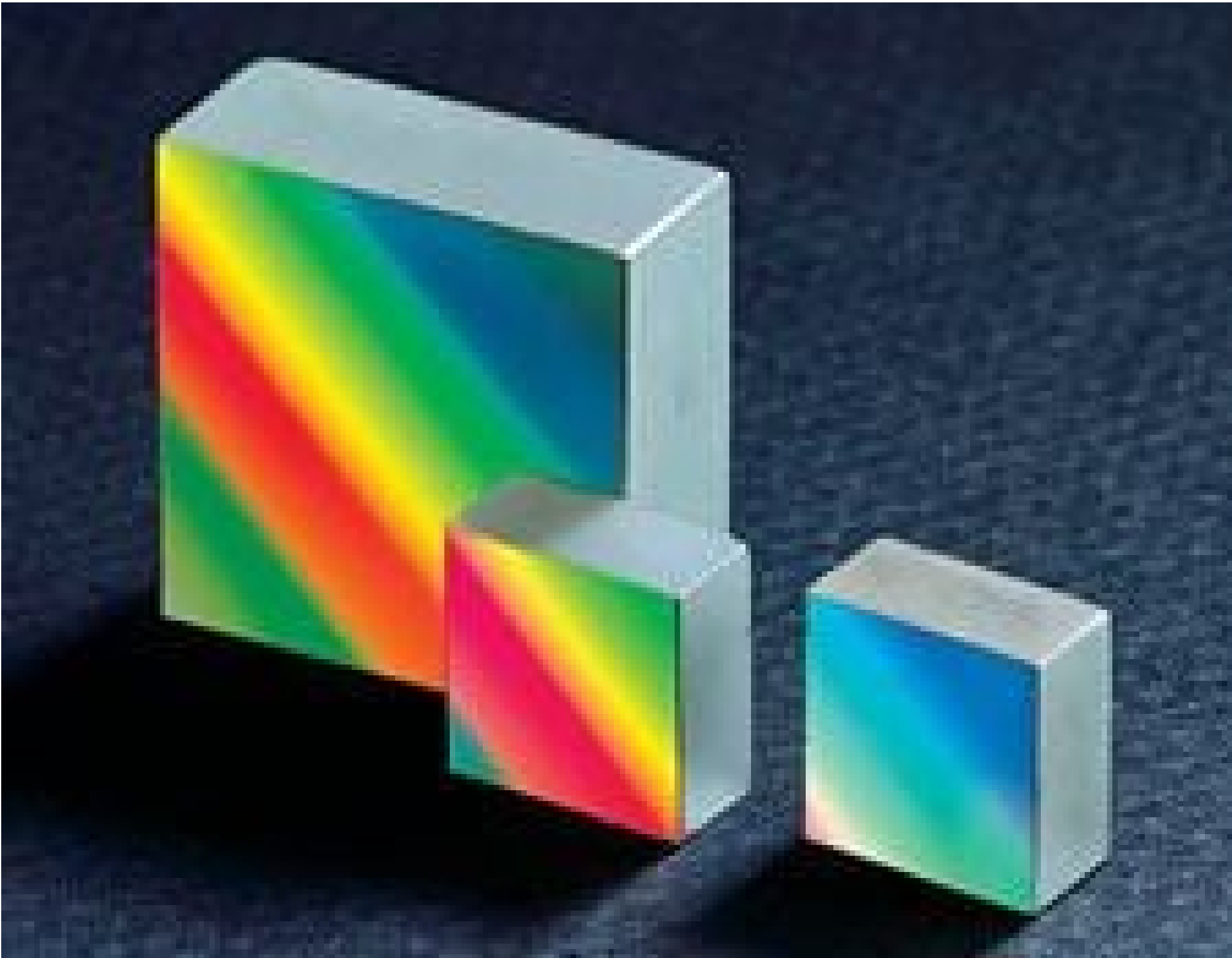

Stock #43-849 3-4 DAYS



1



€135,00

ADD TO CART

Qty 1+

€135,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
830

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
800

Blaze Angle (°):
19.38

Dimensions (mm): 12.7 x 12.7 ±0.5
Clear Aperture (%): 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 12.70
Substrate: ☐ Float Glass
Thickness (mm): 6.00 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 12.70
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View