

**TECHSPEC® 8" Length, 1/4-20 Stud, Steel Post**



Stock #59-009 CLEARANCE [CONTACT US](#)

- 1 + €15<sup>25</sup>

**ADD TO CART**

Volume Pricing	
Qty 1+	€15,25 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

**General**

English **Type:**

**Physical & Mechanical Properties**

203.20 **Length (mm):**

8.0 **Length (inches):**

12.70 **Diameter (mm):**

Diameter (inches):  
0.5

## Threading & Mounting

Male Thread:  
1/4-20

## Regulatory Compliance

RoHS 2015:  
Compliant

Certificate of Conformance:  
[View](#)

REACH 241:  
Compliant


## Product Details

Adapter #58-983 is included. Additional [thread adapters](#) available separately.

- Male 8-32 or 1/4-20 Stud, Female 1/4-20 Base
- Posts Include Interchangeable Male Stud and Removable Base S.H.S.S.
- Available in Variety of Lengths
- [Metric Versions Also Available](#)

TECHSPEC® English Stainless Steel Mounting Posts include a 1/4" long male thread stud adapter that is easily interchangeable with other adapters to ensure compatibility between these posts and any optical mount. Removing the included adapter reveals female 8-32 threads on the post. Each optical post also has a thru-hole to allow an Allen wrench or other tool to rotate the post easily. Thread values are laser engraved on each post for quick identification and integration. TECHSPEC English Stainless Steel Mounting Posts are offered in a variety of lengths. [Metric Versions are also available for purchase.](#)

## Technical Information

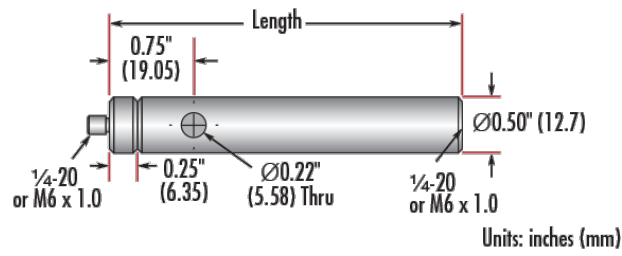

#68-230		
Stock No.	Description	Qty
<a href="#">#59-751</a>	Steel Post, 1" Length	1
<a href="#">#59-752</a>	Steel Post, 1.5" Length	1
<a href="#">#58-999</a>	Steel Post, 2" Length	2
<a href="#">#59-754</a>	Steel Post, 3" Length	2
<a href="#">#59-000</a>	Steel Post, 4" Length	2
<a href="#">#59-008</a>	Steel Post, 6" Length	1
<a href="#">#59-009</a>	Steel Post, 8" Length	1

#68-229		
Stock No.	Description	Qty
<a href="#">#58-960</a>	Steel Post, 1" Length	1
<a href="#">#58-961</a>	Steel Post, 1.5" Length	1
<a href="#">#58-962</a>	Steel Post, 2" Length	2
<a href="#">#58-964</a>	Steel Post, 3" Length	2
<a href="#">#58-965</a>	Steel Post, 4" Length	2
<a href="#">#58-966</a>	Steel Post, 6" Length	1
<a href="#">#58-967</a>	Steel Post, 8" Length	1