

## 90° Angle Mount



#39-355 90° Angle Mount

Stock **#39-355** [CONTACT US](#)

-

1

+

€80<sup>00</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1+         | €80,00 each                   |
| Need More?     | <a href="#">Request Quote</a> |

 Prices shown are exclusive of VAT/local taxes

### Product Downloads

#### General

Mounting Adapter

Type:

#### Physical & Mechanical Properties

63.5 x 50.8 x 38.1

Dimensions (mm):

Black Stainless Steel

Construction:

Weight (lbs):

2½L x2 Wx1½H

Dimensions (inches):

Threading & Mounting

3/4-16

Mounting Threads:

Regulatory Compliance

Compliant

RoHS 2015:

View

Certificate of Conformance:

Compliant

Reach 250:

Product Details

• Swivel Arm for Added Flexibility

• 90° Angle Mounts Connect Horizontal Arms onto Vertical Posts

• Ring Mounts for Increased Versatility


• [Imaging System Bases](#), [Rack and Pinion Focusing Mounts](#), and [Stainless Steel Posts](#) Also Available

Accessories for Imaging Systems are available to increase the versatility of an imaging system. Products in this family include a swivel arm, Infinity Microscope, 90° angle mount, and ring mounts. The swivel arm adds an axis of rotation to the rack and pinion-focusing mounts. The swivel arm can rotate around a vertical post, and the rack and pinion focus mount can rotate around the ¼" post attached to the swivel arm. The Infinity microscope mounting adapter is compatible with Rack and Pinion Mount [#39-357](#) and reduces the thru hole diameter to 58mm. The 90° angle mount, offered in Accessories for Imaging Solutions, allows the mounting of posts at 90° in optical systems. Ring mounts are available for attaching light sources, articulating arms, straight posts, or any ¼-20 accessory to standard mounting hardware.

Features

90° Angle Mount [#39-355](#) features two ¾" thru holes at 90° with locking knobs. All Ring Mounts feature ¼-20 mounting hole, set screw for securing post, or optical component within the inner diameter. Swivel Arm [#03-684](#) features a 0.75" diameter post which accepts rack and pinion focusing mount and allows swivel movement. Infinity Mounting Adapter [#39-358](#) features male and female T-thread to replace 24mm tube section of infinity lens.

Technical Information

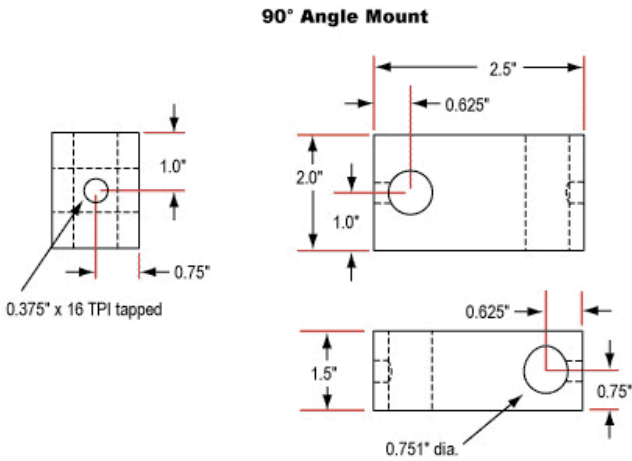

| Stock No.               | A      | T      | O.D.  | I.D.  |
|-------------------------|--------|--------|-------|-------|
| <a href="#">#54-263</a> | 0.375" | 0.5"   | 2.5"  | 1.5"  |
| <a href="#">#54-264</a> | 0.375" | 0.5"   | 1.75" | 0.75" |
| <a href="#">#54-265</a> | 0.271" | 0.375" | 1.25" | 0.5"  |

Units: inches