


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

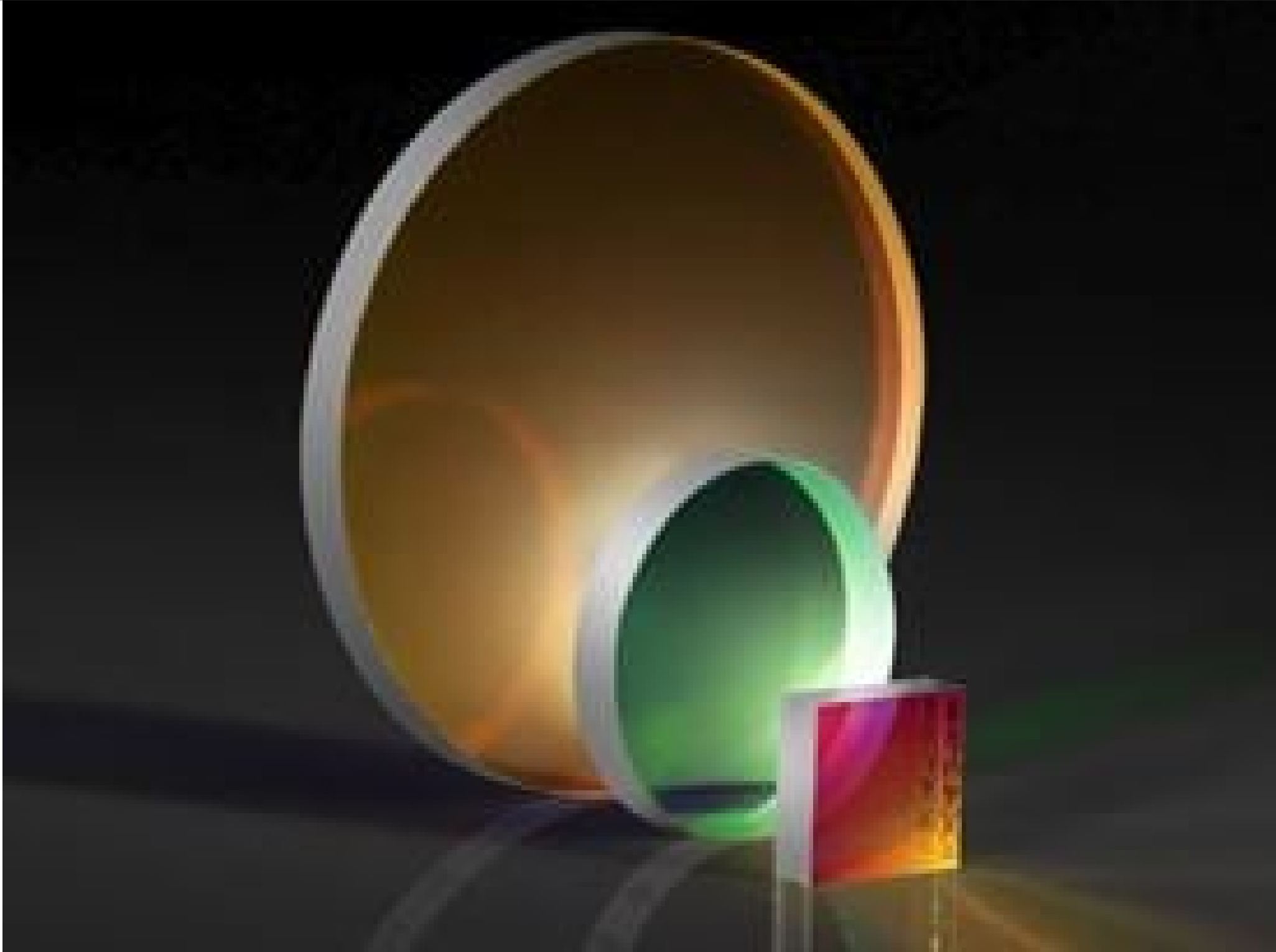

OD 2.0 Shortpass Filters

Stock #15-244 3-4 DAYS



1



€45,00

ADD TO CART

Qty 1-9

€45,00

Qty 10+

€40,50

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):  
6.00 x 6.00 +0.00/-0.20

Angle of Incidence (°):  
0

Optical Density OD (Average):  
≥2.0

|                                                                |
|----------------------------------------------------------------|
| <b>Cut-Off Wavelength (nm):</b><br>950.00 ±19                  |
| <b>Substrate:</b> <a href="#">BOROFLOAT®</a>                   |
| <b>Length (mm):</b><br>6.00                                    |
| <b>Coating:</b><br>Hard Coated                                 |
| <b>Rejection Wavelength (nm):</b><br>1025 - 1250               |
| <b>Surface Quality:</b><br>60-40                               |
| <b>Thickness (mm):</b><br>2.00 ±0.10                           |
| <b>Transmission (%):</b><br>≥85                                |
| <b>Transmission Wavelength (nm):</b><br>500 - 900              |
| <b>Type:</b><br>Shortpass Filter                               |
| <b>Width (mm):</b><br>6.00                                     |
| <b>Clear Aperture (%):</b><br>90                               |
| <b>Environmental Durability:</b><br>ML-STD-810F, Section 507.4 |
| <b>Physical Durability:</b><br>ML-C-48497A, Section 3.4.1      |
| <b>Wavelength Range (nm):</b><br>500 - 1250                    |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS:</b><br><a href="#">Compliant</a>                  |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |