

Adapter Plate for #55-028



#55-037

#55-037

Stock **#55-037** 20+ In Stock

-

1

+

€37⁷⁵

ADD TO CART

Volume Pricing	
Qty 1-9	€37,75 each
Qty 10+	€33,90 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Type:

Adapter Brackets & Plates

Physical & Mechanical Properties

Length (inches):

1.57

Length (mm):

40.00


40 x40 x5	Dimensions (mm):
Threading & Mounting	
Mounting Threads: (4) M2 x0.4, (4) M3 x0.5, (1) 1/4-20	
Regulatory Compliance	
RoHS 2015: Compliant	
Certificate of Conformance: View	
Reach 247: Compliant	

Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide ±5° Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise ±5° angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

Technical Information

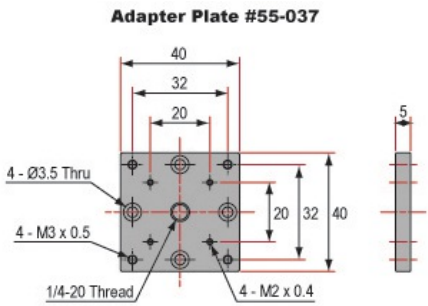

Units: mm