 



Hoya B410 (UV-VIS) 25mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

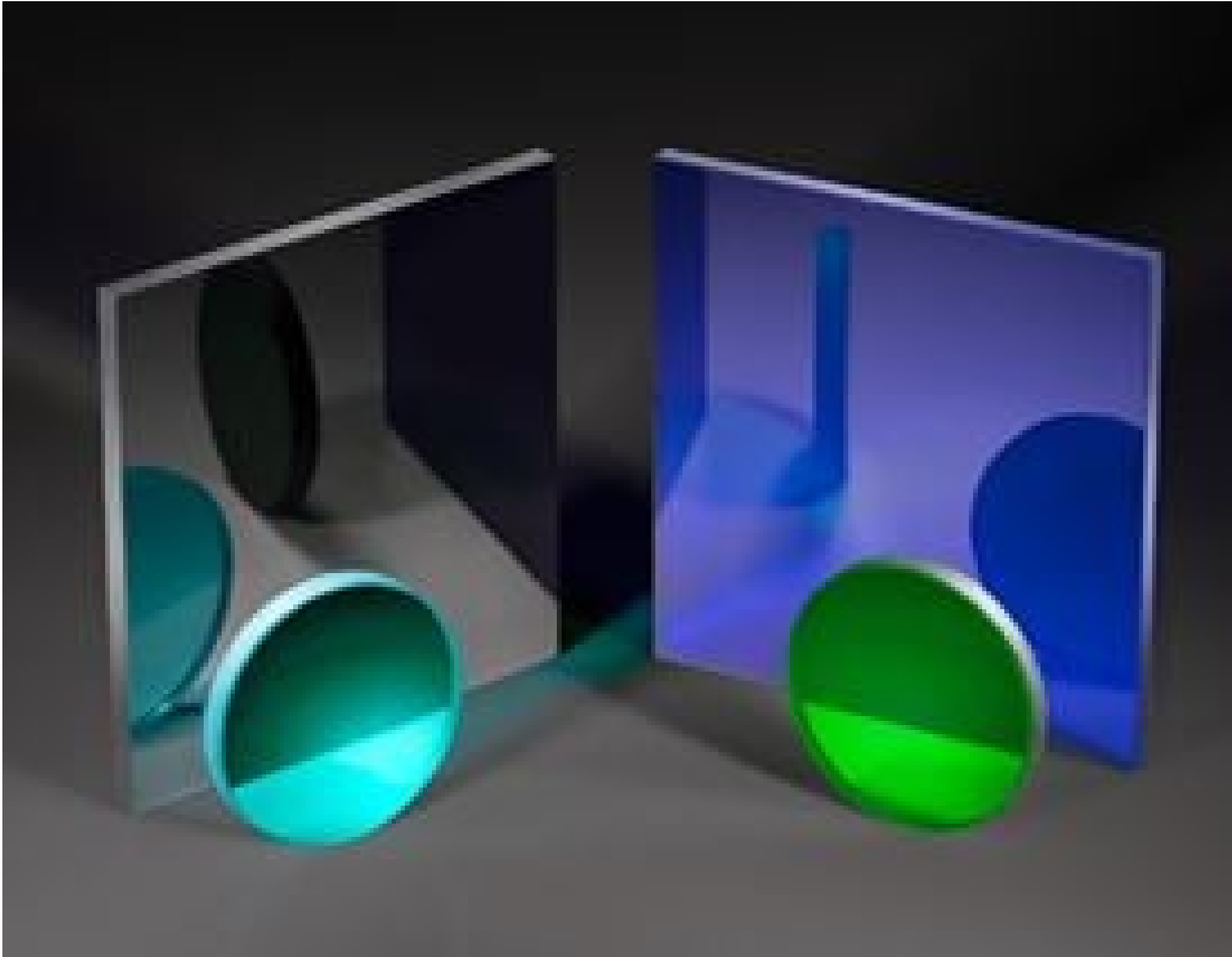

Stock **#34-432** 3-4 DAYS

- 1 + **€63,00**

ADD TO CART

Qty 1-10
€63,00
Qty 11+
€56,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
25.0 x 25.0

Center Wavelength CWL (nm):

410.00
Density (g/cm³): 2.27
Full Width-Half Max FWHM (nm): 232.00
Glass/Filter Number: Hoya B410
Substrate: ☐ Colored Glass
Length (mm): 25.00
Coating: Uncoated
Color: Blue
Surface Quality: 80-50
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 25.00
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View