

 

In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

Hoya B460 (UV-VIS) 25mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

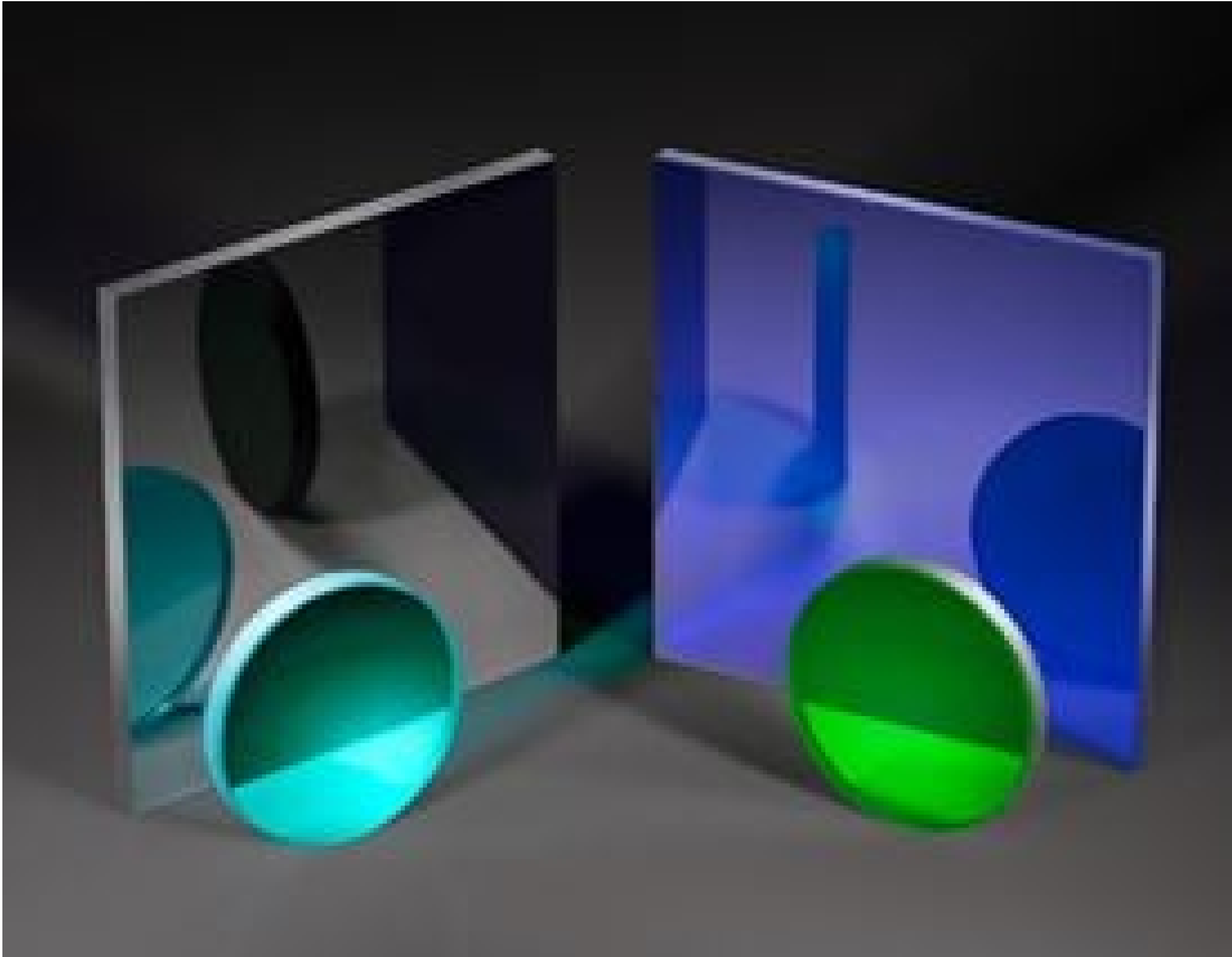

Stock #34-444 3-4 DAYS

1 €63,00

ADD TO CART

Qty 1-10

€63,00

Qty 11+

€56,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
25.0 x 25.0

Center Wavelength CWL (nm):

460.00
Density (g/cm³): 2.60
Full Width-Half Max FWHM (nm): 200.00
Glass/Filter Number: Hoya B460
Substrate: ☐ Colored Glass
Length (mm): 25.00
Coating: Uncoated
Color: Blue-Green
Surface Quality: 80-50
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 25.00
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View