


Color Scanner Test Target

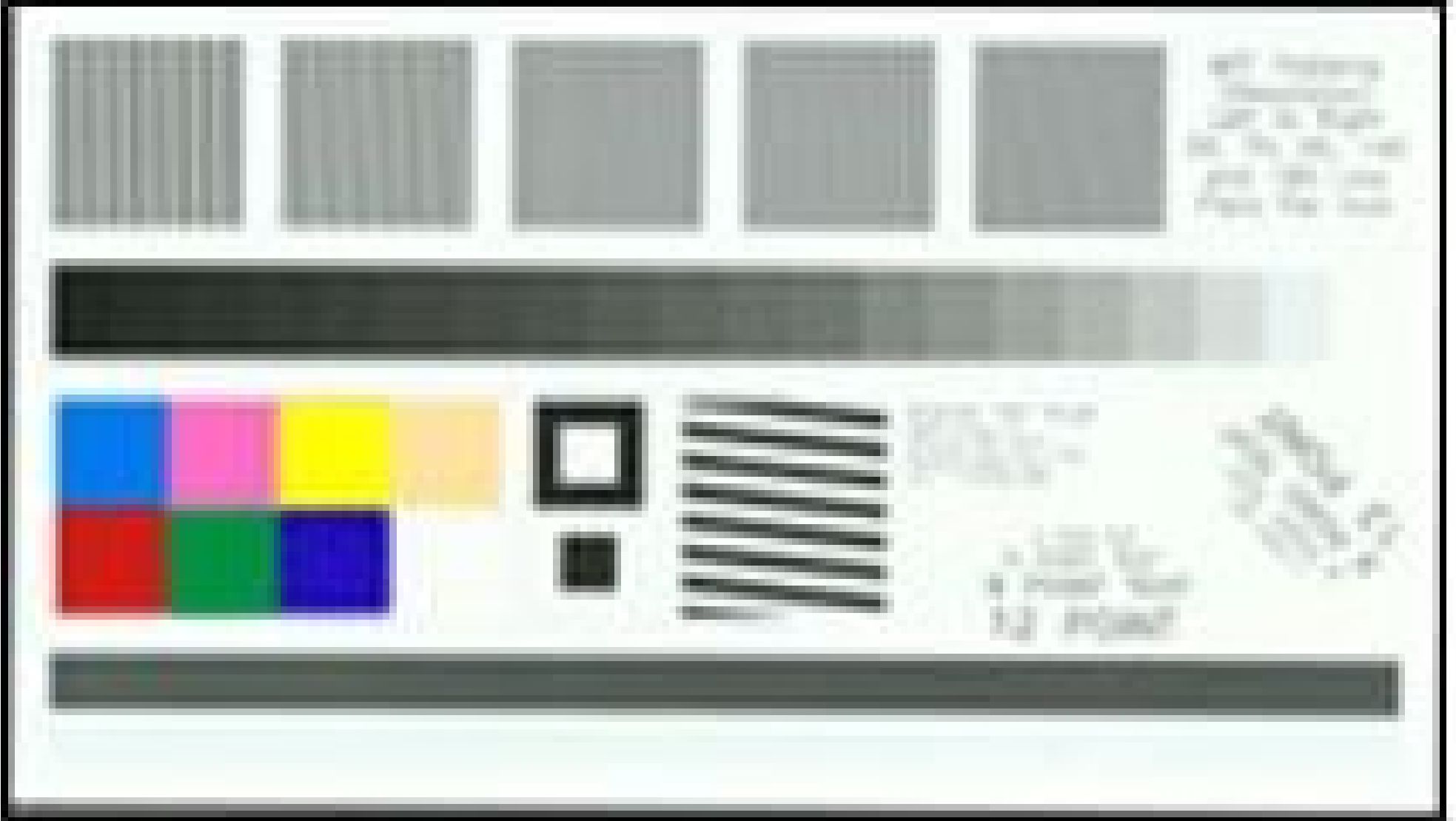

Stock #58-197 **3 In Stock**

- 1 + €322.⁰⁰

ADD TO CART

Volume Pricing

| | |
|------------|-------------------------------|
| Qty 1-4 | €322,00 each |
| Qty 5+ | €306,30 each |
| Need More? | Request Quote |

Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Note:

Colors on Target: CYAN Azure Blue #72, MAGENTA True Pink #337, YELLOW Medium Yellow # 10, AMBER Bastard Amber #02, RED Fire #19, GREEN Moss Green #89, BLUE Brilliant Blue #69, WHITE

NIST Certification:

No

Physical & Mechanical Properties

110 x 190 **Pattern Size (mm):**

110 x 190 **Dimensions (mm):**

Optical Properties

Photo Paper **Substrate:**

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

Reach 235:
[Compliant](#)

Product Details

- Ideal for Evaluation of Color Flatbed Scanners

The Color Scanner Test Target is a critical tool for evaluating the performance of any digital imaging or scanning device. The target features 5 resolution patterns (30, 75, 95, 140, and 180 linepairs per inch), 20 density step wedge, various alphanumeric, 2 constant density strips, 8 color patches, and 10:1 ratio angle ronchi ruling.

Technical Information

