 



Hoya G530 (VIS) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

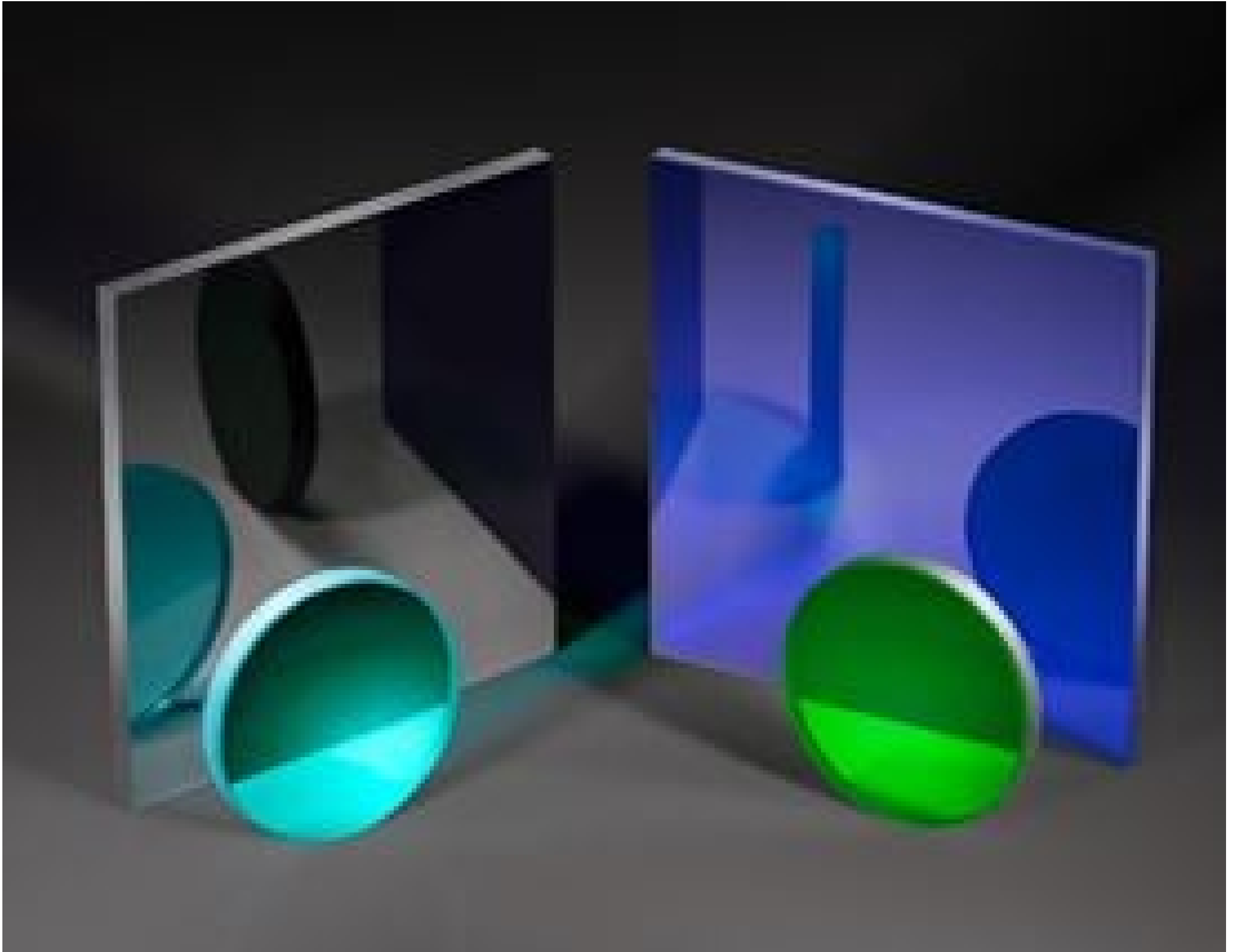

Stock #34-435 3-4 DAYS

⊖ 1 ⊕ **€45,00**

ADD TO CART

Qty 1-10
€45,00

Qty 11+
€40,00

Volume Pricing
[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm):
530.00

Density (g/cm³):
3.12

Full Width-Half Max FWHM (nm):
50.00

Glass/Filter Number:
[Hoya G530](#)

Substrate:
Colored Glass

Coating:
Uncoated

Color:
Green

Surface Quality:
80-50

Thickness (mm):
2.50

Thickness Tolerance (mm):
±0.2

Type:
Bandpass Filter

Wavelength:
VIS

Parallelism (arcmin):
≤1

Dimensional Tolerance (mm):
+0/-0.25

Regulatory Compliance

RoHS 2015:
[Exempt](#)

Reach 224:
[Compliant](#)

Certificate of Conformance:
[View](#)