

[All Products](#) / [Lights and Illumination](#) / [Advanced Illumination High Intensity](#)

[See all 5 Products in Family](#)


# Green, UltraSeal

See More by [Advanced Illumination](#)

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region: European Union

Submit

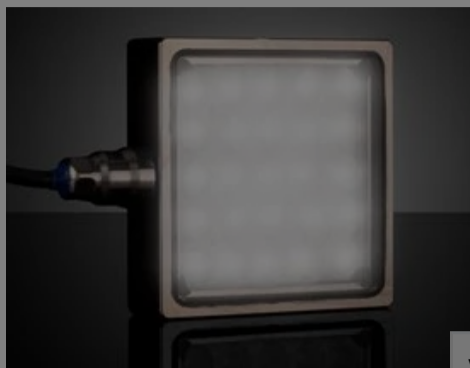

Advanced Illumination High Intensity UltraSeal Washdown Spot Lights

Stock #21-972 **CLEARANCE** 1 In Stock

1

€1.092<sup>,95</sup>

ADD TO CART

Volume Pricing	
Qty	€1.092,95
1+	each
Need More?	<a href="#">Request Quote</a>

Prices shown are exclusive of VAT/local taxes

### Product Downloads

- STEP:step
- PDF Drawing:pdf
- IGES:igs
- Spec Sheets:pdf
- eDrawing:eprt
- EO Spec Sheet
- [Download All](#)

**Note:** This item requires accessories for use | [Learn More](#)

## General

<b>Model Number:</b>	SL316M-530IC	<b>LED Lifetime (hours):</b>	50,000
<b>Number of LEDs:</b>	25	<b>Type of Illumination:</b>	LED Illuminator
<b>Manufacturer:</b>	Advanced Illumination	<b>Geometry:</b>	Spot Light
<b>Illumination Mode:</b>	Constant		

## Physical & Mechanical Properties

<b>Weight (g):</b>	290
--------------------	-----

## Optical Properties

<b>Color:</b>	Green	<b>Wavelength (nm):</b>	530
---------------	-------	-------------------------	-----

## Hardware & Interface Connectivity

<b>Connector:</b>	Flying Leads	<b>Power Supply:</b>	Power Supply Required and Sold Separately: USA: <a href="#">#66-855</a> Europe: <a href="#">#66-855</a> Japan: <a href="#">#89-513</a> Korea: <a href="#">#33-773</a> China: <a href="#">#66-855</a>
-------------------	--------------	----------------------	---

<b>Length of Cable (m):</b>	2
-----------------------------	---

## Environmental & Durability Factors

**Operating Temperature (°C):** 0 to +60

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

**Select Your Country/Region:**

## Regulatory Compliance

**Certificate of Conformance:** [View](#)

## Product Details

- IP69K Certified for Extreme Washdown Environments
- Ideal for Hygienic and Aseptic Manufacturing Applications
- Intensity of Over 60,000 Lux at 300mm Working Distance

Advanced Illumination High Intensity UltraSeal Washdown Spot Lights are ideal for extreme environments including high pressure steam cleaning and prolonged liquid immersion. Available in five colors, these spot lights feature high intensity output and consistent uniformity. These spot lights are IP69K certified and their proprietary nickel finish ensures better thermal conductivity than stainless steel while the sealed design reduces the potential for material buildup and improves cleanability. Advanced Illumination High Intensity UltraSeal Washdown Spot Lights can be used in hygienic inspection environments, aseptic manufacturing, and food and beverage applications.

## Accessories

**Note:** Compatible accessories for individual stock numbers may vary. If unsure about which accessories work with your products, please contact us [here](#).

	Title	Compare	Stock Number	Price	Buy
<a href="#">MORE+</a>	24V Power Supply with Tinned Leads		#66-855	€95,00 <a href="#">Request Quote</a>	6 In Stock <input type="text" value="1"/>

## Related Products



Advanced Illumination UltraSeal Washdown Bar Lights



Advanced Illumination High Intensity In-Line Lights



Cw Series Fixed Focal Length Lenses



IDS Imaging uEye+ FA IP65/67 PoE Cameras