

Iris Mount for 19.8mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock **#53-918** 20+ In Stock

-

1

+

€47²⁵

ADD TO CART

Volume Pricing	
Qty 1-4	€47,25 each
Qty 5-9	€41,70 each
Qty 10-25	€38,70 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

19.8	Compatible Iris Diameter (mm):
30.8	Outer Diameter (mm):

6.35	Thickness (mm):
Threading & Mounting	
8-32	Mounting Threads:
4-40	Set Screw Thread:

Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:

Compliant	Reach 235:
-----------	------------

Product Details


• Multiple Iris Diameter Options Available

• Durable Anodized Aluminum Construction

• Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

Technical Information

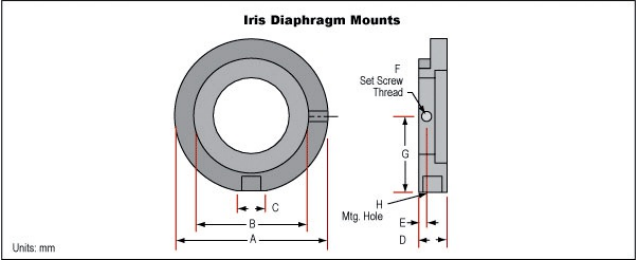

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	#53-918
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	1/4-20	#53-919
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	1/4-20	#53-920
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	1/4-20	#53-921
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	#54-862
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	1/4-20	#54-863
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	1/4-20	#54-864
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	1/4-20	#54-865

Technical drawing of an Iris Diaphragm Mount. The top view shows a circular flange with dimensions A (outer diameter), B (inner diameter), and C (flange thickness). The side view shows the mounting post with dimensions D (post diameter), E (post length), F (set screw thread length), G (post height), and H (mounting hole diameter). Labels include 'Set Screw Thread' and 'Mtg. Hole'. The text 'Units: mm' is at the bottom left.