

## Iris Mount for 28mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock #23-125 **20+ In Stock**

⊖ 1 ⊕ €46<sup>00</sup>

**ADD TO CART**

### Volume Pricing

|            |                               |
|------------|-------------------------------|
| Qty 1-4    | €46,00 each                   |
| Qty 5-9    | €41,50 each                   |
| Qty 10-25  | €37,50 each                   |
| Need More? | <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### Physical & Mechanical Properties

Compatible Iris Diameter (mm):  
28.0

Outer Diameter (mm):  
52.0

Thickness (mm):  
6.00

Optical Axis Height (mm):  
25.40

## Threading & Mounting

Mounting Threads:  
M4 x0.7 and 8-32

Set Screw Thread:  
4-40

## Regulatory Compliance

RoHS 2015:  
[Compliant](#)

Certificate of Conformance:  
[View](#)


Reach 235:  
[Compliant](#)

## Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

## Technical Information

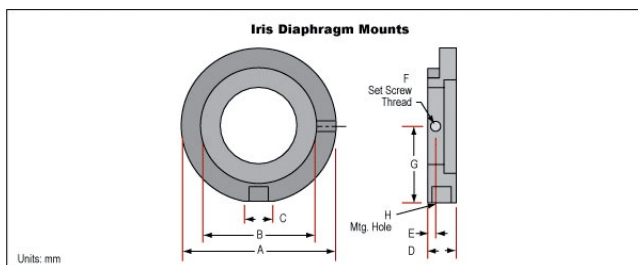

| Iris Diameter | A    | B    | C    | D    | E   | F    | G    | H      | Stock No.               |
|---------------|------|------|------|------|-----|------|------|--------|-------------------------|
| 19.8          | 30.8 | 19.8 | 6.1  | 6.35 | 2.5 | 4-40 | 15.1 | 8-32   | <a href="#">#53-918</a> |
| 37.0          | 50.8 | 37.0 | 9.0  | 9.5  | 2.8 | 6-32 | 25.0 | 1/4-20 | <a href="#">#53-919</a> |
| 53.0          | 66.0 | 53.0 | 9.9  | 9.5  | 3.0 | 6-32 | 32.7 | 1/4-20 | <a href="#">#53-920</a> |
| 70.0          | 86.0 | 70.0 | 10.1 | 9.5  | 3.8 | 6-32 | 42.7 | 1/4-20 | <a href="#">#53-921</a> |
| 21.0          | 32.0 | 21.0 | 6.2  | 9.5  | 3.2 | 4-40 | 15.7 | 8-32   | <a href="#">#54-862</a> |
| 38.0          | 52.0 | 38.0 | 9.1  | 9.5  | 3.2 | 6-32 | 25.6 | 1/4-20 | <a href="#">#54-863</a> |
| 54.0          | 67.0 | 54.0 | 8.9  | 9.5  | 3.8 | 6-32 | 33.2 | 1/4-20 | <a href="#">#54-864</a> |
| 72.0          | 88.0 | 72.0 | 10.3 | 11.5 | 3.8 | 6-32 | 43.7 | 1/4-20 | <a href="#">#54-865</a> |

□