

[All Products](#) / [Optomechanics](#) / [Iris Diaphragm Mounts](#)

[See all 25 Products in Family](#)

# Iris Mount for 70mm



Iris Mount for 70mm Outer Diameter Iris Diaphragms #53-921

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region: European Union

Submit

1

€92<sup>00</sup>

ADD TO CART

Volume Pricing	
Qty 1-4	€92,00 each
Qty 5-9	€81,60 each
Qty 10-25	€75,60 each
Need More?	<a href="#">Request Quote</a>

Prices shown are exclusive of VAT/local taxes

### Product Downloads

- STEP:step
- PDF Drawing:pdf
- IGES:igs
- eDrawing:eprt
- EO Spec Sheet
- [Download All](#)

## Physical & Mechanical Properties

Compatible Iris Diameter (mm): 70.0

Outer Diameter (mm): 86.0

Thickness (mm): 9.50

## Threading & Mounting

Mounting Threads: 1/4-20

Set Screw Thread: 6-32

## Regulatory Compliance

RoHS 2015: **Compliant**

Certificate of Conformance: [View](#)

Reach 235: **Compliant**

## Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

## Technical Information

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

**Select Your Country/Region:**

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	<a href="#">#53-918</a>
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	1/4-20	<a href="#">#53-919</a>
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	1/4-20	<a href="#">#53-920</a>
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	1/4-20	<a href="#">#53-921</a>
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	<a href="#">#54-862</a>
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	1/4-20	<a href="#">#54-863</a>
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	1/4-20	<a href="#">#54-864</a>
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	1/4-20	<a href="#">#54-865</a>

## Related Products



English Stainless Steel  
Mounting Posts



Post Holders



Adjustable Height Post Holders

## Frequently Purchased Together




#32-617 - 50mm Max. Aperture,  
Iris Diaphragm  
€139,00

Qty



#53-913 - 50mm Max. Aperture,  
Stainless Steel Iris Diaphragm  
€189,00

Qty

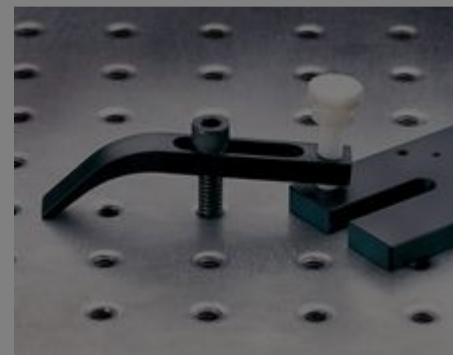

#53-356 - Tie-Down Table Clamp  
€30,00

Qty



#53-910 - 12mm Maximum  
Aperture, Stainless Steel  
Iris Diaphragm  
€47,25

Qty



## Resources

**Media Type**

- FAQ
- Glossary
- Application Note
- Trending in Optics
- Video

? FAQ

Demountable

? FAQ

Demountable

GLOSSARY

Axial Runout

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

**Select Your Country/Region:**

GLOSSARY

Concentricity

GLOSSARY

Inverted Load Capacity

GLOSSARY

Tangent Arm Drive

[View More](#)