

[See all 25 Products in Family](#)

Iris Mount for 70mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921

Stock **#53-921** **20+ In Stock**

⊖ 1 ⊕ €92.⁰⁰

ADD TO CART

Volume Pricing

Qty 1-4	€92,00 each
Qty 5-9	€81,60 each
Qty 10-25	€75,60 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

70.0 **Compatible Iris Diameter (mm):**

86.0 **Outer Diameter (mm):**

9.50 **Thickness (mm):**

Threading & Mounting

Mounting Threads:
 $\frac{1}{4}$ -20

Set Screw Thread:
 6-32

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)


Reach 235:
[Compliant](#)

Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

Technical Information

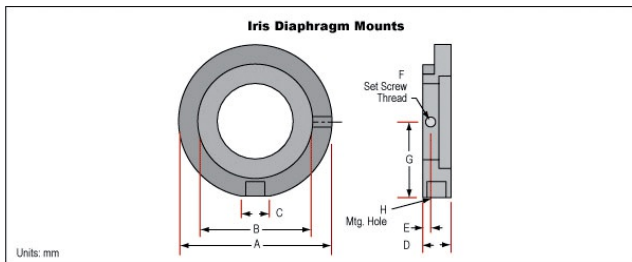

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	#53-918
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	$\frac{1}{4}$ -20	#53-919
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	$\frac{1}{4}$ -20	#53-920
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	$\frac{1}{4}$ -20	#53-921
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	#54-862
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	$\frac{1}{4}$ -20	#54-863
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	$\frac{1}{4}$ -20	#54-864
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	$\frac{1}{4}$ -20	#54-865

