


Medium Thick Base Single Movement

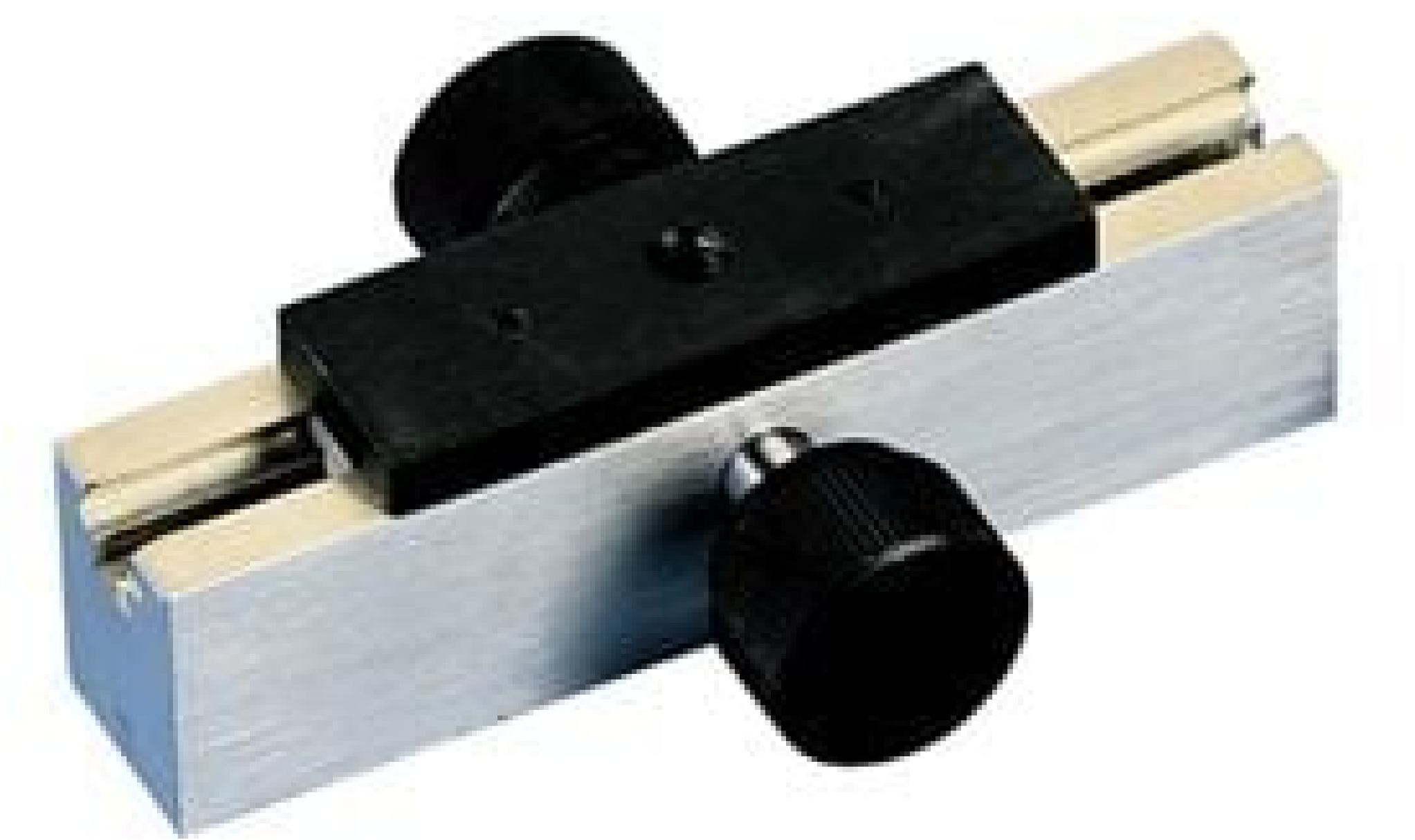

#03-681

Stock #03-681 □ In Stock



1



€213,00

ADD TO CART

Qty 1-9

€213,00

Qty 10+

€188,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Dovetail

Type of Drive:
Rack and Pinion

Type: English
Stage Size (mm): 20 x 100
Travel (mm): 40 (±20)
Load Capacity (kg): 3.5 Horizontal, 2.1 Vertical
Mounting Threads: Stage: (1) ¼-20 Base: (3) ¼-20
Note: Not Lockable
Straight Line Accuracy (µm): 50
Travel Per Knob Rotation (mm): 15
Weight (g): 422
Table Size (mm): 20 x 60

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 235: Contains SVHC(s)