

Nikon 200mm Tube Lens

See More by [Nikon](#)



#58-520: Nikon 200mm Tube Lens

Stock **#58-520** **20+ In Stock**

-

1

+

€600⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	€600,00 each
Need More?	Request Quote

● Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Type:	
Tube Lens	
Manufacturer:	
Nikon	

Physical & Mechanical Properties

Length (mm):	
29.00	
Maximum Diameter (mm):	
36.0	

Optical Properties

Focal Length FL (mm):	
-----------------------	--

200.00	
1X	Magnification:
400 - 700	Wavelength Range (nm):
26.5	Field Number (mm):
32.0	Entrance Pupil Diameter (mm):

Threading & Mounting

M38 x 0.5	Mounting Threads:
-----------	-------------------

Regulatory Compliance


Compliant	RoHS 2015:
View	Certificate of Conformance:

Product Details

• Superior UV Transmission
• High Numerical Aperture Designs
• Feature Low Auto-Fluorescence Materials

Nikon CFI Super Fluor Objectives are designed to provide superior transmission to ultraviolet applications operating down to 340nm, including for use with fluorochromes indo-1, fura-2, and fluo-3, or for photo-activation of caged compounds. Nikon CFI Super Fluor Objectives are designed using low auto-fluorescence materials along with high numerical apertures to guarantee sharp, bright fluorescence images. These microscope objectives have been optimized for improved signal-to-noise ratios at short wavelengths.

Technical Information

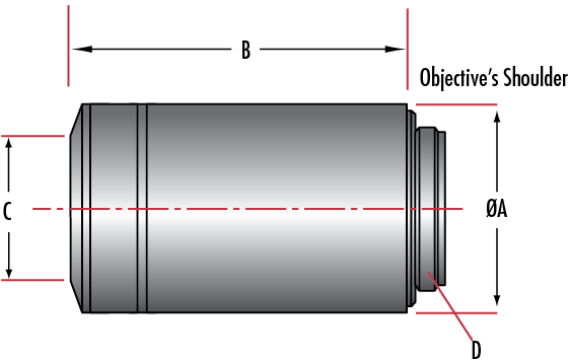

Dimensions (mm)						
Stock No.	Magnification	Parafocal Length	A	B	C	D
#88-374	4X	60.06	30.0	44.4	19.7	M25 x 0
#88-375	10X	60.06	32.0	58.7	8.0	M25 x 0
#88-376	20X	60.06	33.5	58.9	9.0	M25 x 0
#88-377	40X	60.06	33.0	59.6	7.5	M25 x 0