


## ISO-16067-1 Reflective Scanner Target

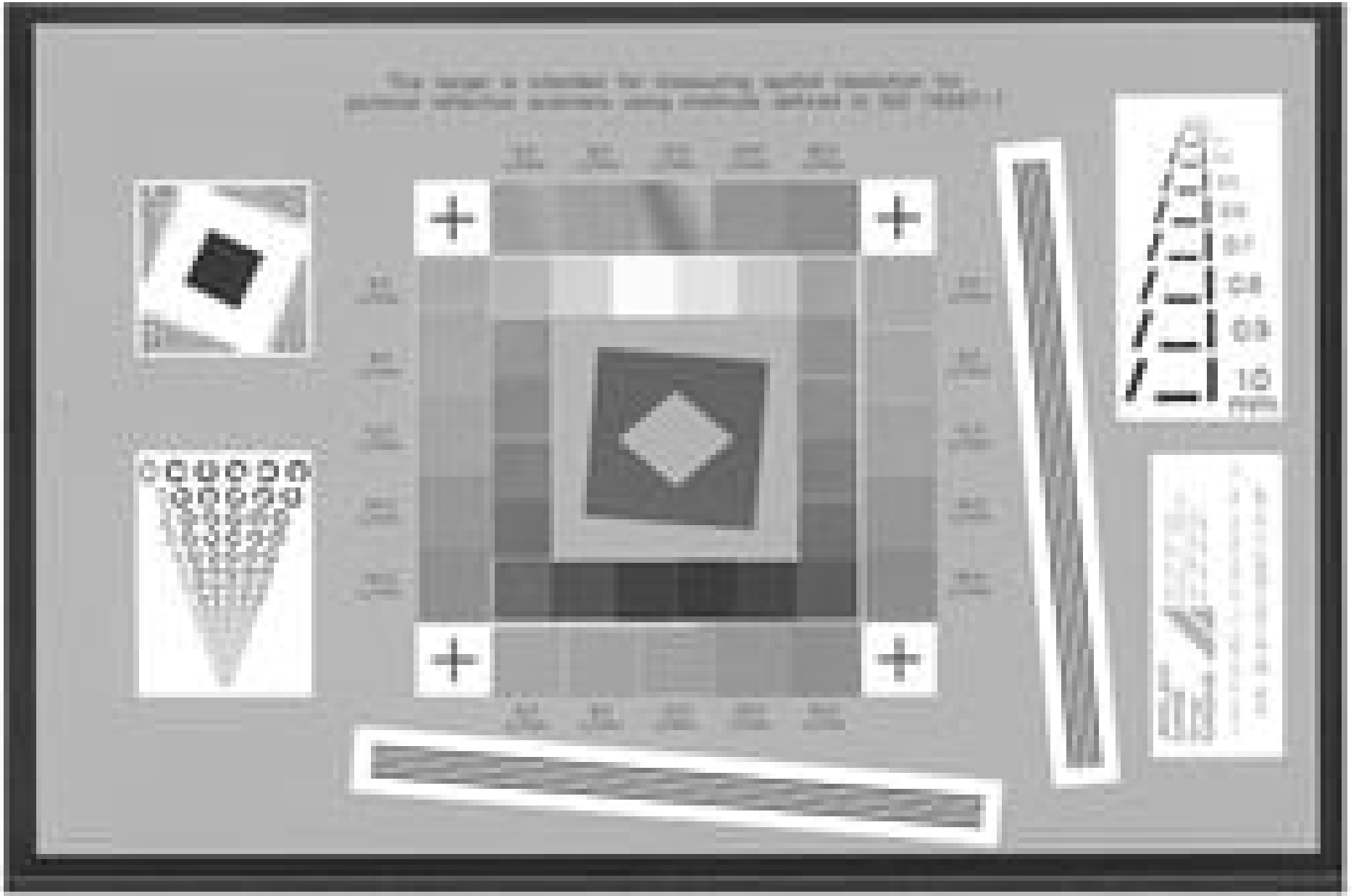

Stock #58-196 **1 In Stock**

⊖ 1 ⊕ €388.<sup>00</sup>

**ADD TO CART**

### Volume Pricing

Qty 1-4	€388,00 each
Qty 5+	€369,70 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### General

NIST Certification:  
No

### Physical & Mechanical Properties

Length (mm):  
152.00

Width (mm):  
100.00

## Optical Properties

Black and White Photo Paper

**Substrate:**

6 - 40 lp/mm

**Resolution:**

## Regulatory Compliance

[Compliant](#)

**RoHS 2015:**

[View](#)

**Certificate of Conformance:**

[Compliant](#)

**Reach 235:**

## Product Details

- Complies with the ISO 16067-1 Standard
- Designed to Test Digital Scanning Systems

The Reflective Scanner Test Target is designed to measure the reflective light resolution and imaging characteristics of digital scanning systems, in compliance with ISO 16067-1 specifications. Target patterns include the Landolt Ring, alphanumeric resolution and slant edge charts, grey step patches, and horizontal, vertical, and slanted ronchi ruling patterns (6 - 40 lp/mm).