 



SCHOTT BG18, 12.5mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

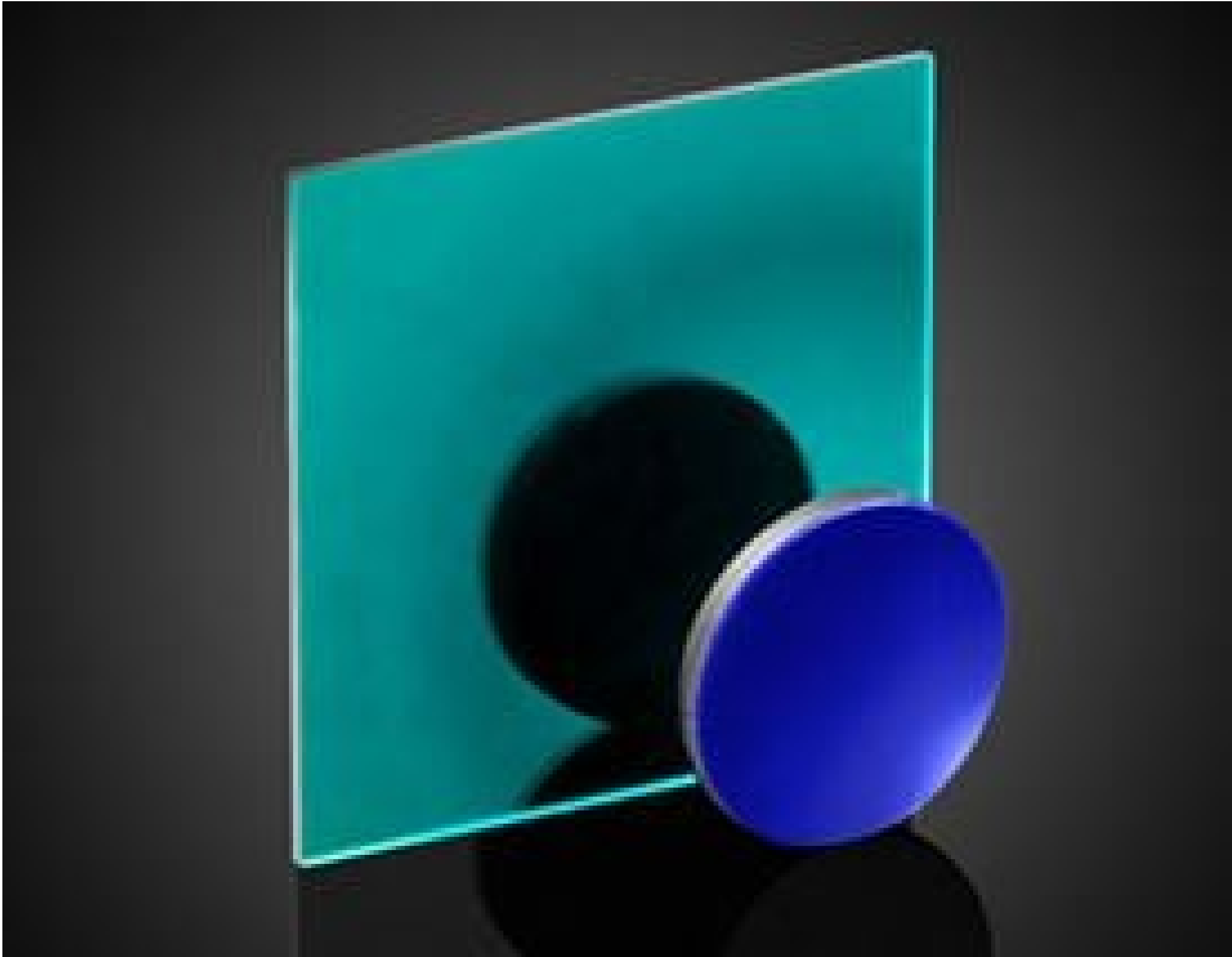

Stock **#16-363** 3-4 DAYS

[Additional Bandwidths](#)

- 1 + **€41,00**

ADD TO CART

Qty 1-10
€41,00
Qty 11+
€37,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50

Center Wavelength CWL (nm):
493.00

Density (g/cm³): 2.68
Glass/Filter Number: SCHOTT BG18
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.54
Surface Quality: 60-40
Transformation Temperature (°C): 482
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: VS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--