 



# SCHOTT BG18, 50mm Sq., 2mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

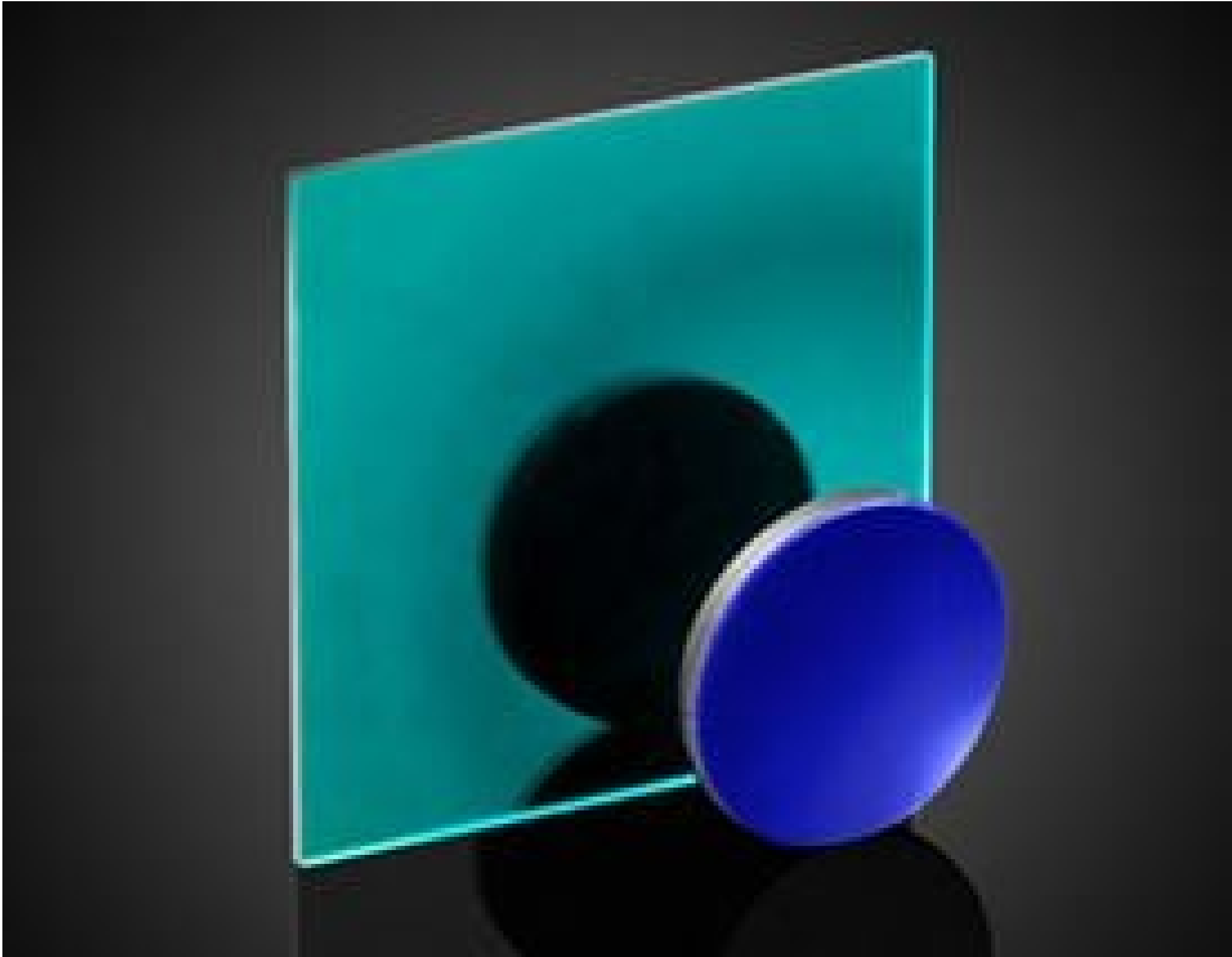

Stock **#14-410** ☐ In Stock

-

1

+

**€88,00**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| €88,00                        |
| Qty 11+                       |
| €78,00                        |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

## Get Product Downloads

**Dimensions (mm):**  
50.0 x 50.0

**Center Wavelength CWL (nm):**  
493.00

|                                                     |
|-----------------------------------------------------|
| Density (g/cm³):<br>2.68                            |
| Glass/Filter Number:<br><a href="#">SCHOTT BG18</a> |
| Length (mm):<br>50.00                               |
| Coating:<br>Uncoated                                |
| Color:<br>Blue-Green                                |
| Index of Refraction n <sub>d</sub> :<br>1.54        |
| Surface Quality:<br>60-40                           |
| Transformation Temperature (°C):<br>482             |
| Thickness (mm):<br>2.00 ±0.2                        |
| Type:<br>Bandpass Filter                            |
| Wavelength:<br>VIS                                  |
| Width (mm):<br>50.00                                |
| Bevel:<br>Protective as needed                      |

Regulatory Compliance

|                                                     |
|-----------------------------------------------------|
| RoHS:<br><a href="#">Compliant</a>                  |
| Certificate of Conformance:<br><a href="#">View</a> |