

In order to provide more accurate inventory information, please select your shipping country.


Select Your Country/Region: European Union



SUBMIT

SCHOTT BG25, 12.5mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

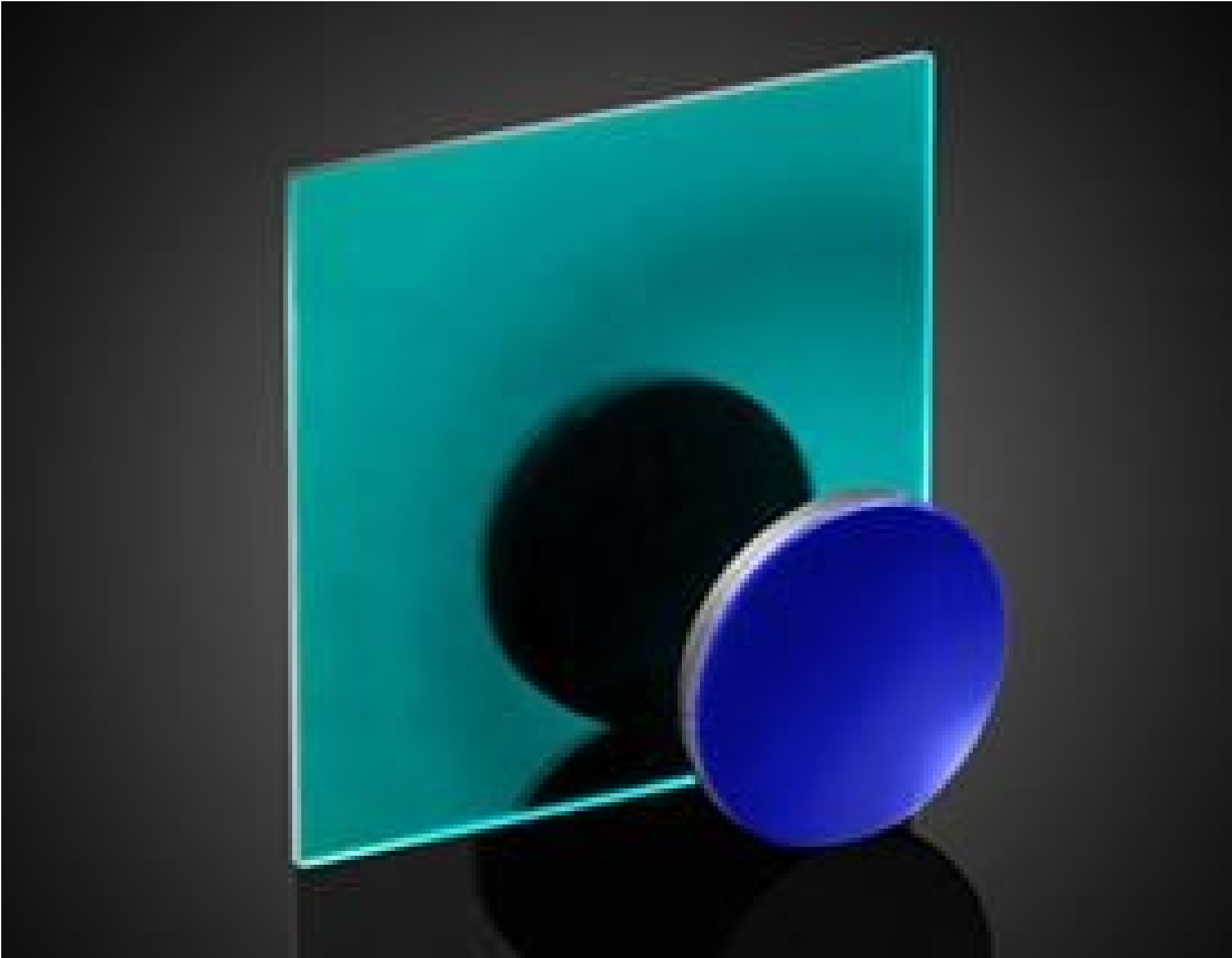

Stock #16-359 3-4 DAYS

[Additional Bandwidths](#)



1



€41,00

ADD TO CART

Qty 1-10

€41,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50

Center Wavelength CWL (nm):
400.00

Density (g/cm³): 2.56
Glass/Filter Number: SCHOTT BG25
Coating: Uncoated
Color: Blue-Violet
Index of Refraction n_d: 1.51
Surface Quality: 60-40
Transformation Temperature (°C): 487
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--