

In order to provide more accurate inventory information, please select your shipping country:

 

Select Your Country/Region: European Union



SUBMIT

SCHOTT BG25, 50mm Sq., 3mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

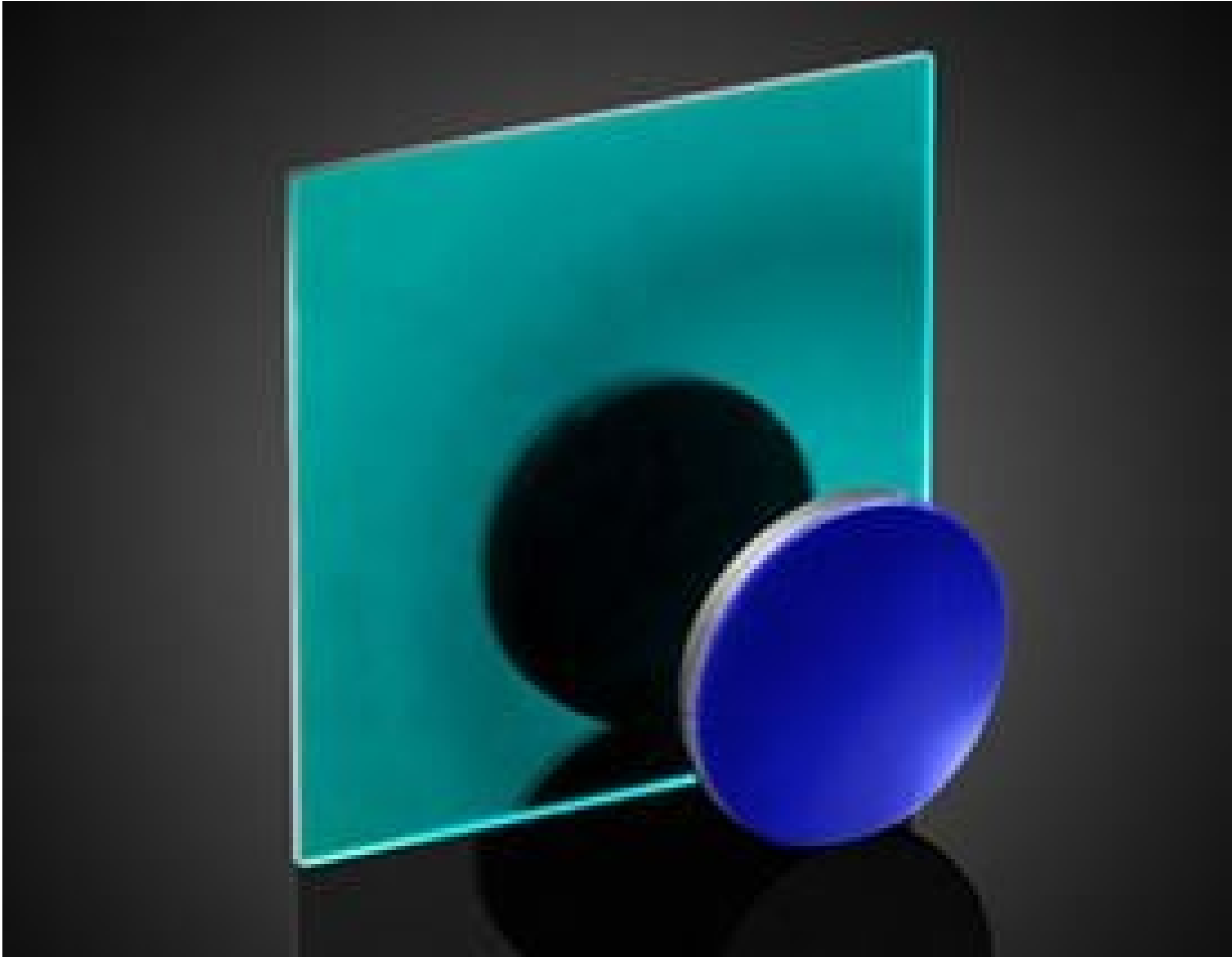

Stock **#14-414** ☐ In Stock



1



€88,00

ADD TO CART

Qty 1-10

€88,00

Qty 11+

€78,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
400.00

Density (g/cm³): 2.56
Glass/Filter Number: SCHOTT BG25
Length (mm): 50.00
Coating: Uncoated
Color: Blue-Violet
Index of Refraction n_d: 1.51
Surface Quality: 60-40
Transformation Temperature (°C): 487
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View