


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

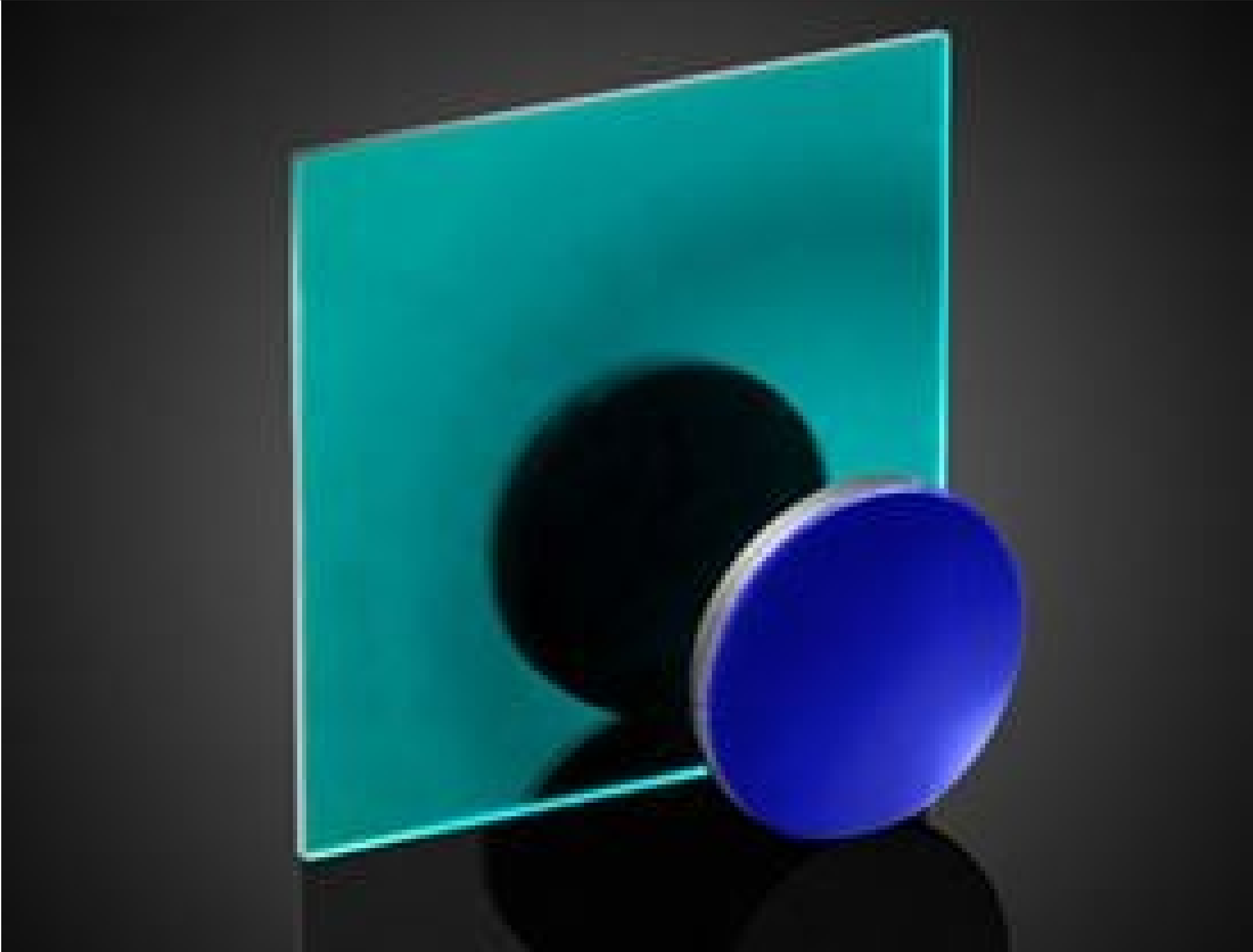

Stock #16-392 3-4 DAYS

[Additional Bandwidths](#)



1



€41,00

ADD TO CART

Qty 1-10

€41,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50

Center Wavelength CWL (nm):
470.00

Density (g/cm³): 2.66
Glass/Filter Number: SCHOTT BG38
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.53
Surface Quality: 60-40
Transformation Temperature (°C): 482
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: VS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--