


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

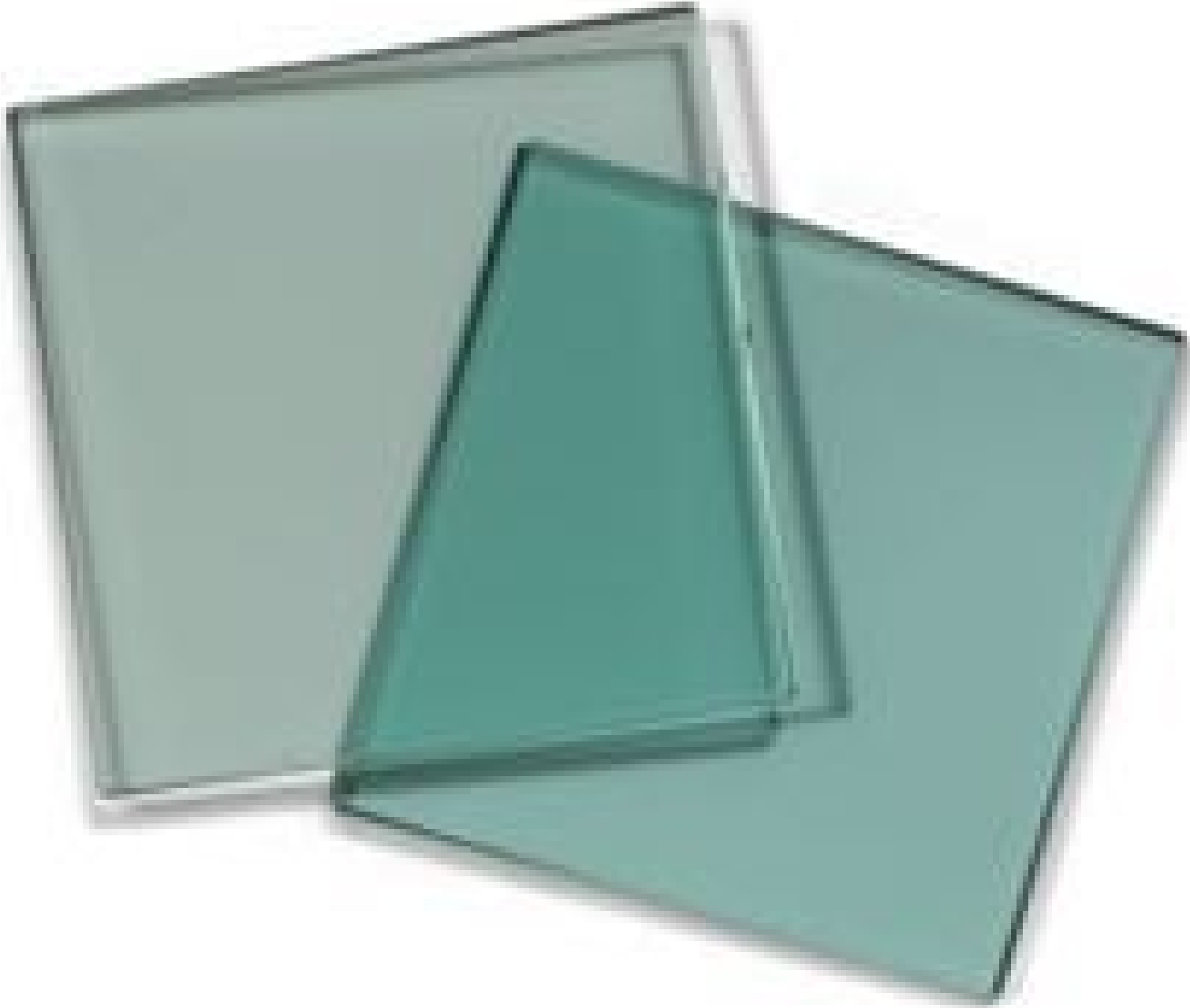

Stock #14-548 □ In Stock



1



€90,00

ADD TO CART

Qty 1-10

€90,00

Qty 11+

€80,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
50.0 x 50.0

Density (g/cm³):
2.52

Glass/Filter Number:

[SCHOTT KG2](#)

Substrate: ☐
Heat Absorbing Glass

Length (mm):
50.00

Operating Temperature (°C):
300 Maximum

Coating:
Uncoated

Index of Refraction n_d :
1.51

Surface Quality:
60-40

Transformation Temperature (°C):
605

Thickness (mm):
2.00 ±0.2

Type:
IR Cut-Off Filter

Width (mm):
50.00

Dimensional Tolerance (mm):
±0.2

Reflection Factor P_d :
0.92

Wavelength Range (nm):
300 - 2700

Bevel:
Protective as needed

Regulatory Compliance

RoHS:
[Compliant](#)

Certificate of Conformance:
[View](#)