


TECHSPEC[®] T-Mount Iris Diaphragm Mount

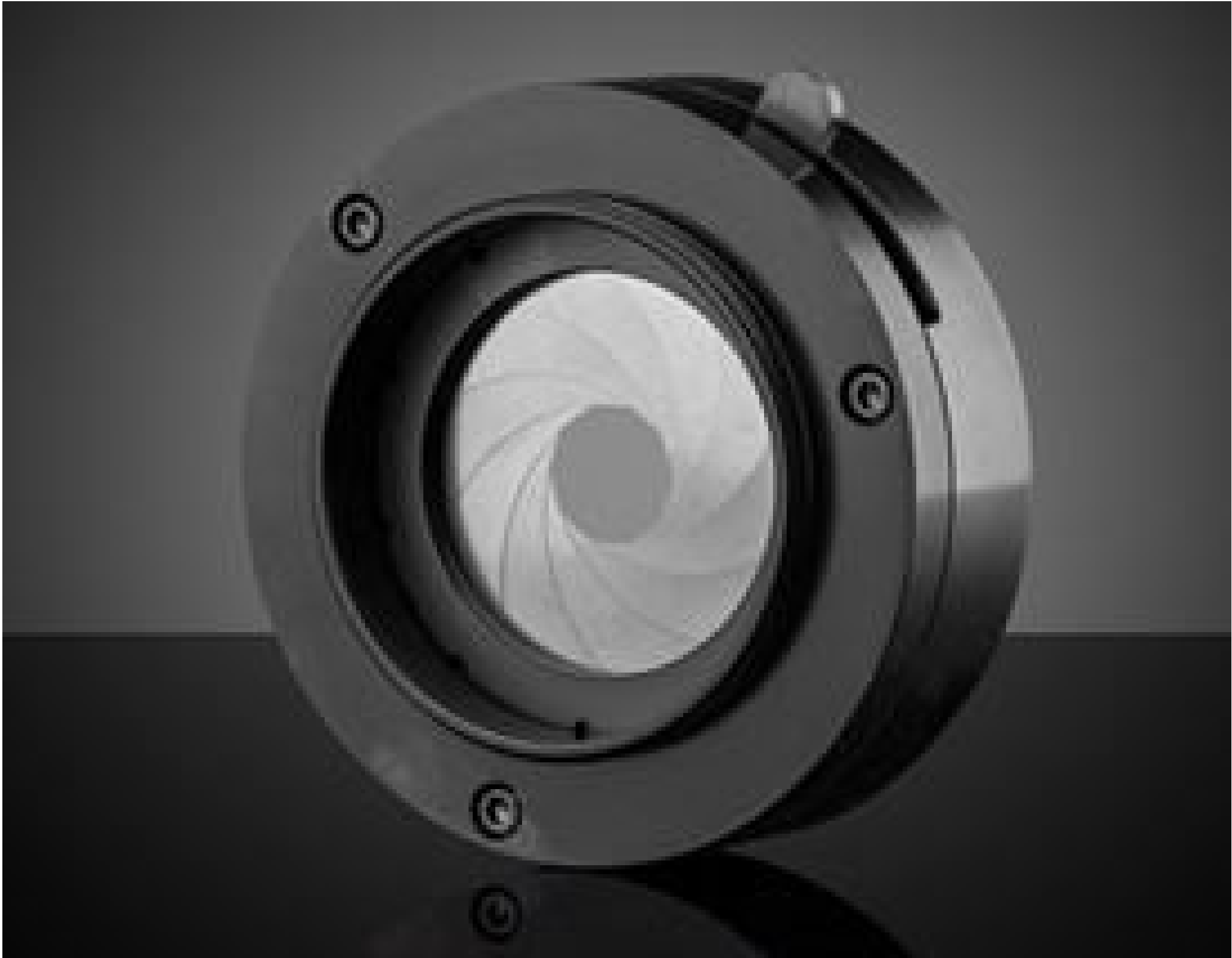

T-Mount Iris Diaphragm Mount, #52-299

Stock **#52-299** [CONTACT US](#)

-

1

+

€226⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	€226,00 each
Qty 5-9	€199,40 each
Qty 10-25	€184,00 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Iris Diaphragm

Function:

Physical & Mechanical Properties

18.13

Extension Length (mm):

Total Length (mm):

22.0	
	Outer Diameter (mm):
58.0	
	Clear Aperture CA (mm):
1.2 - 30.0	

Threading & Mounting	
	Thread Type:
T-Mount	

Regulatory Compliance	
	RoHS 2015:
Compliant	
	Reach 219:
Compliant	
	Certificate of Conformance:
View	

Product Details

- Variable Apertures for C, S, and T-Mount Systems
- Male and Female Thread at Opposite Ends for Easy Integration
- Adjusted via Rotating Ring or Lever for Precision Control

TECHSPEC® C, S, and T-Mount Iris Diaphragm Mounts feature iris diaphragms that allow for precision control over the internal aperture within a system. Using male and female threads, these mounts can be placed anywhere within a C, S, or T-Mount system. The apertures can be adjusted via a rotating ring for the C-Mount version, with a 4mm lever for the S-Mount version and with a 5mm lever for the T-Mount version. TECHSPEC C, S, and T-Mount Iris Diaphragm Mounts add 12mm, 12mm, and 18mm to the system length, respectively. These mounts are ideal for providing control over the f/#, field stop diameter, and overall energy throughput of a C, S, or T-Mount system.

NOTE: The iris planes sit approximately 15mm, 8mm, and 12mm from the female ends of the TECHSPEC C, S, and T-Mount Iris Diaphragm Mounts, respectively.

Technical Information

