


TECHSPEC® Two Knob Stage Only

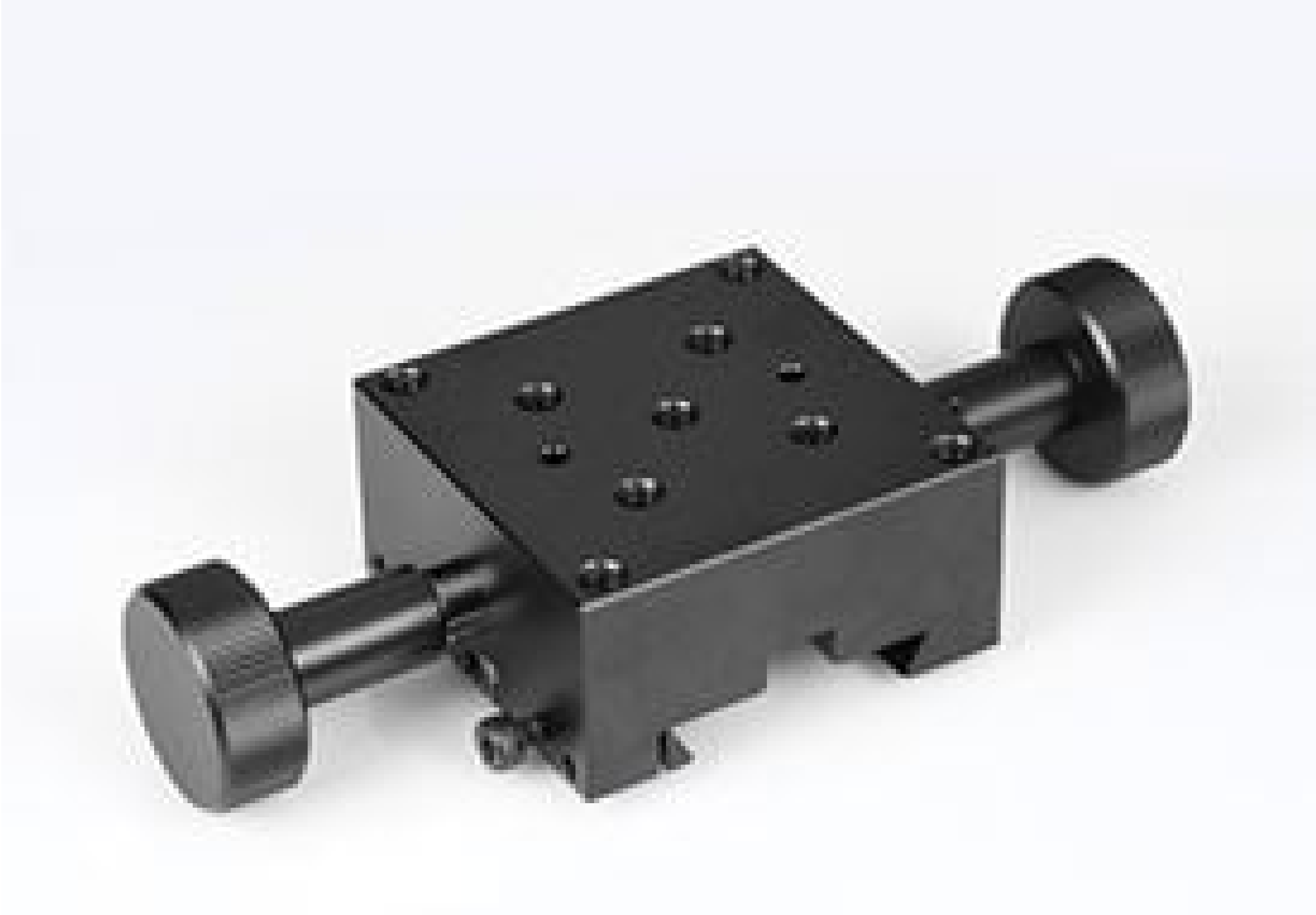

#59-332

Stock #59-332 3-4 DAYS

⊖ 1 ⊕

€154,00

ADD TO CART

Qty 1+

€154,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:  
Linear (X)

Type of Drive:  
Rack and Pinion

Type:  
English

Stage Size (mm):  
62 x 60

Construction:

|                                                   |
|---------------------------------------------------|
| Black Anodized Aluminum                           |
| <b>Graduation (inches):</b><br>0.1 (Vernier)      |
| <b>Load Capacity, Normal (kg):</b><br>5           |
| <b>Load Capacity, Vertical (kg):</b><br>2         |
| <b>Mounting Threads:</b><br>(9) ¼-20              |
| <b>Note:</b><br>Two Knob Carrier                  |
| <b>S.H.C.S. C'bore:</b><br>N/A                    |
| <b>Travel Per Knob Rotation (inches):</b><br>0.71 |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Exempt</a>                |
| <b>Reach 224:</b><br><a href="#">Contains SVHC(s)</a>      |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

